

LOC AI	DIST 00	REVISIONS			
P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	INITIAL REVISION	18JAN2018	BM	GS

**Ausführung:  
Workmanship:**


- Leichte Handhabung  
Easy handling
- Linearer Hub  
Straight action principle
- Entriegelbare Zwangssperre  
Ratchet release
- Kontaktpositionierung mit Isolationsstopblech  
Contact positioning with insulation-stop
- Präzise geschliffene Profile  
Precisely ground profiles
- Oberfläche brüniert  
Burnished surface
- Ergonomisch geformte Soft-Handgriffe  
Farbe: blau (ähnl. Pantone 3015C)  
Ergonomically formed soft-grips  
Colour: blue (similar Pantone 3015C)
- Voll recyclefähig  
RoHS Richtlinie 2011/65/EU konform  
Fully recyclable  
RoHS Directive 2011/65/EU compliant

**Abmessungen:  
Dimensions:**

- Länge: ca. 195 mm  
Length: approx. 195 mm
- Breite: ca. 63 mm  
Width: approx. 63 mm
- Gewicht: ca. 290 g  
Weight: approx. 290 g

**Anwendungsbereich:  
Application range:**

Leiterquerschnitt Cross section range AWG	Kontakt-Typ: Contact Type:
30-28	Quick-Verbinder
28-24 / Lahn- und Mischlitze	Quick Contacts

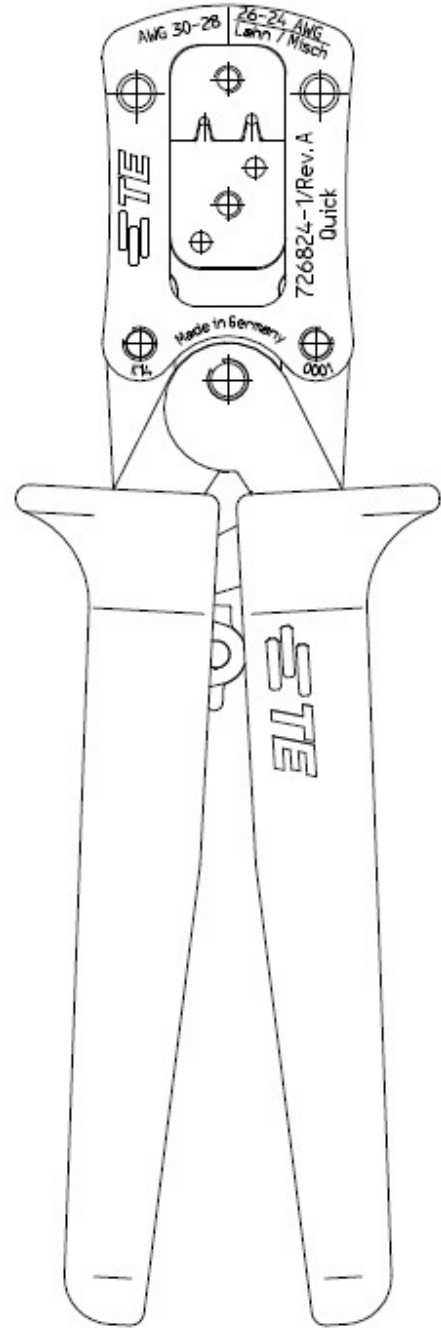


 
RELEASED FOR PUBLICATION

ALL INTERNATIONAL RIGHTS RESERVED.

BY TYCO ELECTRONICS CORPORATION.

© COPYRIGHT

THIS DRAWING IS UNPUBLISHED.

DIMENSIONS: mm	DWN B. Muth	18JAN2018	MATERIAL	FINISH
	CHK G. Stegmayer	18JAN2018	 TE Connectivity	
TOLERANCES UNLESS OTHERWISE SPECIFIED:	APVD G. Stegmayer	18JAN2018		
	PRODUCT SPEC		TELFIX Handzange	
0 PLC ± -	APPLICATION SPEC		SIZE	CAGE CODE
1 PLC ± -			A4	00779
2 PLC ± -			DRAWING NO	RESTRICTED TO
3 PLC ± -			©=726824-1	-
4 PLC ± -				
ANGLES ± -	WEIGHT	0,290kg		
	CUSTOMER DRAWING		SCALE 1:1	SHEET 1 of 1
				REV A