

732-8308-01




(0,027 max.)
 $\varnothing 0,68$ max.

(0,041 max.)
 $\varnothing 1,04$ max.

13,4 (0,526)

Clé / Key

1

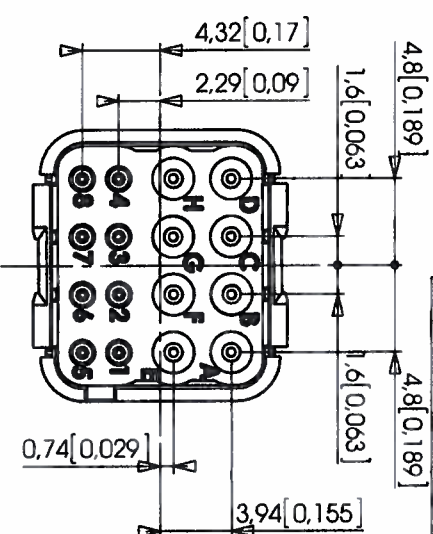

Température d'utilisation: -55°C à +175°C

Contacts: Alliage de cuivre, doré
Tenue de tension: 1300 V eff. ; 50Hz

Masse: 8g Maxi

Dimensions: Millimètres (pouces)

Operating temperature range: -55°C to +175°C

 
Material: Thermoplastic and yellow fluorosilicone

Contacts: Copper alloy, gold plated

Withstand voltage: 1300 V eff ; 50Hz

Weight: 8g Maxi

Dimensions: Millimeters [inches]



b	07/05/2015	OE040515				
Q	16/07/2013	Creation				
Revision	Date	Observations				
ORIGINE :	DE064/13					
ORIGIN :						
SERIE DMC-M DESIGNATION Module P 99-03 avec contacts à picots droits P Module 99-03 with straight PCB contacts			DATE 16-07-2013	VISA Creation 	VISA Approbation 	
REF : P/N: 732-8308-01						
VERSION			-	-	-	-
REVISION						

THE

Connecteurs Electriques Deutsch

17, rue LAVOISIER - BP 117 - 27091 EVREUX CEDEX 09 - FRANCE

FICHE TECHNIQUE

TECHNICAL DATA SHEET

204-19-C/101