
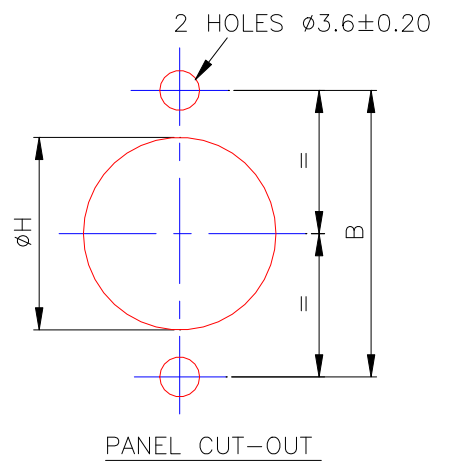
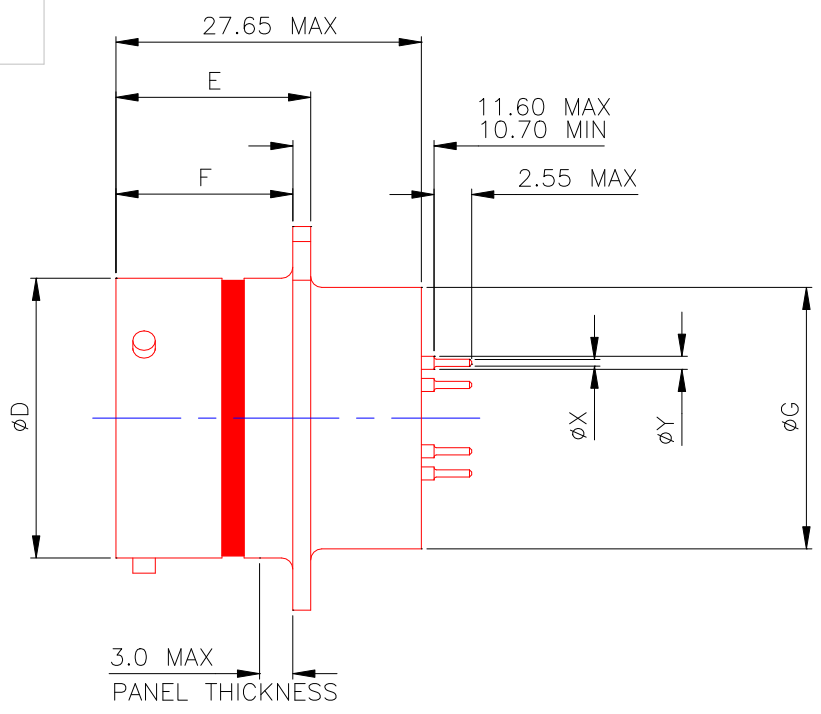


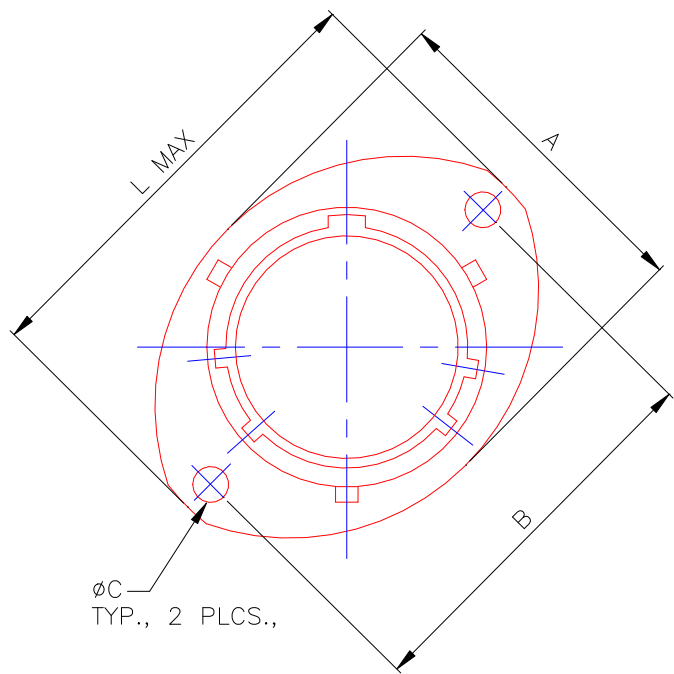

SHELL SIZE	A REF	B ±0.20	C +0.1 -0.0	ØD +0.0 -0.13	E +0.15 -0.0	F +0.0 -0.13	ØG MAX	ØH ±0.10	L MAX
8	16.50	21.40	3.2	12.00	17.21	16.05	11.10	14.50	27.20
10	19.50	25.90	3.2	15.00	17.21	16.05	14.27	17.40	32.00
12	24.00	29.10	3.2	19.05	17.21	16.05	17.44	21.90	35.20
14	27.00	32.50	3.2	22.22	17.21	16.05	20.60	25.00	38.40
16	30.30	34.80	3.2	25.40	17.21	16.05	23.77	28.20	41.00
18	33.70	38.20	3.2	28.57	17.21	16.05	26.94	31.40	44.70
20	37.00	41.60	3.2	31.75	17.21	15.29	30.11	34.60	47.90
22	40.00	44.95	3.2	34.90	17.21	15.29	33.29	37.75	51.10
24	43.30	49.35	3.2	38.10	17.21	15.29	36.46	40.90	55.80

NOTE:-
1. BATCH No. & PART No., BREAKDOWN.

DEUTSCH AS2 ** - ** P/S * - 933C RP654321

SERIES _____
SHELL STYLE _____
ARRANGEMENT _____

BATCH No. _____
MODIFICATION CODE _____
KEYWAY ORIENTATION _____
P=PIN OR S=SOCKET

CONTACT SIZE	ØX MAX	ØY MAX
22	0.72	1.25
20	0.72	1.25
16	1.57	2.61