

REV. B
DCO 300860

TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED


COIL: @ 25°C	CURRENT: 40 mA MAX.
RESISTANCE _____	
NOMINAL VOLTAGE _____	115 VAC - 400 Hz
MUST OPERATE _____	70.0 VAC MAX., 400 Hz
MUST RELEASE _____	25.0 VAC MAX., 8.0 VAC MIN., 400 Hz

ENVIRONMENT:

VIBRATION	33 Hz	TO	3000 Hz	@	30 g's
SHOCK	200 g's		6 MS. DURATION		
TEMPERATURE	-70 °C	TO	+125 °C		

NOTES: OPERATE TIME 15 MS MAX.
RELEASE TIME 50 MS MAX.
CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

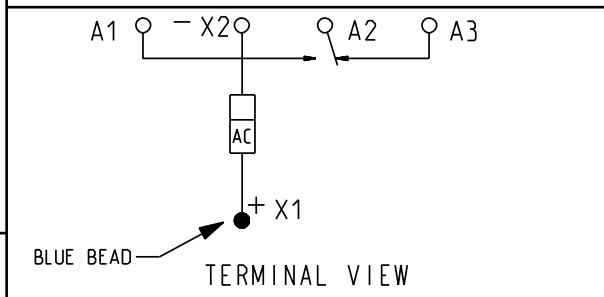

CONTACT RATING: _____
25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
50,000 OPERATIONS

DR. B.D. 21MAY2008 CK. J.M.B. 5/21/08

Tyco Electronics ©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. _____ CATALOG ITEM _____
CUST. NO. _____ REV. _____

TE NUMBER
7-1617748-6

CII PART NUMBER
FCA-125-CX8