

REV. B
DCO 300860

TOLERANCES $\pm .010''$ - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	CURRENT: .04 A MAX.
RESISTANCE _____	
NOMINAL VOLTAGE _____	115 VAC - 400 Hz
MUST OPERATE _____	70.0 VAC MAX., 400 Hz
MUST RELEASE _____	25.0 VAC MAX., 8.0 VAC MIN., 400 Hz


ENVIRONMENT:

VIBRATION	33 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES:

OPERATE TIME	15 MS MAX.
RELEASE TIME	50 MS MAX.
CONTACT BOUNCE	1 MS MAX.

CUSTOMER DATA SHEET

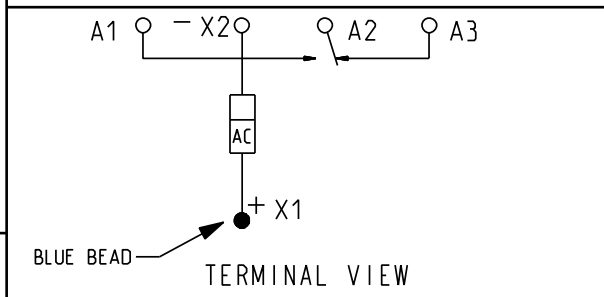

CONTACT RATING:

25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
50,000 OPERATIONS

DR. B.D. 21MAY2008 CK. J.M.B. 5/21/08

Tyco Electronics ©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. _____ CATALOG ITEM _____	TE NUMBER _____
CUST. NO. _____ REV. _____	8-1617748-2

CII PART NUMBER
FCA-125-CY8