


REV. 0  
DCO 300145

COIL: @ 25°C	
RESISTANCE	320 OHMS $\pm 10\%$
NOMINAL VOLTAGE	28.0 VDC
MUST OPERATE	13.5 VDC
MUST RELEASE	6.5 VDC MAX., 2.5 VDC MIN.

ENVIRONMENT:	
VIBRATION	33 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES: OPERATE & RELEASE 10 MS MAX.  
CONTACT BOUNCE 1 MS MAX.  
COIL TRANSIENT SUPPRESSION 42 VDC MAX.

CUSTOMER DATA SHEET

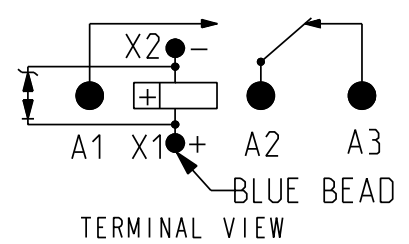

CONTACT RATING:	25 AMPS 28 VDC.
	115 VAC 400 Hz
	RESISTIVE 50,000 OPERATIONS

DR. B.D. 04JAN2005 CK. JMB 1/4/05



CUST. CII STD.  
CUST. NO. \_\_\_\_\_ REV. \_\_\_\_\_  
"FCA-125" RELAY

FCA-125-HX4