

REV. B

DCO 300781


TOLERANCES  $\pm .010"$  - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	320 OHMS $\pm 10\%$
NOMINAL VOLTAGE	28 VDC
MUST OPERATE	13.5 VDC MAX.
	TRANSIENT SUPPRESSION - 42 VDC MAX.
MUST RELEASE	5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES:	OPERATE, RELEASE 10 MS MAX.
	CONTACT STABILIZATION 2.5 MS MAX.
	CONTACT BOUNCE 1 MS MAX.
	CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

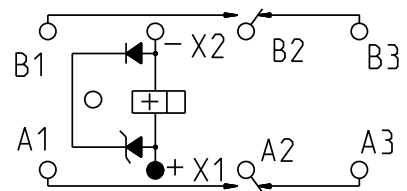

TERMINAL VIEW

CONTACT RATING:	LOW LEVEL
TO 10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE,	
100,000 OPERATIONS	

DR. B.D. 06MAR2008 CK. 3/7/08 J.M.B.

**Tyco Electronics** ©COPYRIGHT 2005  
 TYCO ELECTRONICS CORPORATION  
 ALL INTERNATIONAL RIGHTS RESERVED

CUST. \_\_\_\_\_  
 CUST. NO. M83536/10-019M REV. ---

TE NUMBER  
 1-1617749-3

CII PART NUMBER  
 FCA-210-1019M