

REV. C
DCO 300855


TOLERANCES $\pm .010$ " - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C
 RESISTANCE 320 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 28 VDC
 MUST OPERATE 13.5 VDC MAX.
TRANSIENT SUPPRESSION - 42 VDC MAX.
 MUST RELEASE 5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:
 VIBRATION 33 Hz TO 3000 Hz @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 10 MS MAX.
 CONTACT BOUNCE 1 MS MAX.
 CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

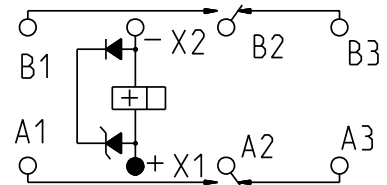

TERMINAL VIEW

CONTACT RATING: 10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE.
100,000 OPERATIONS

DR. B.D. 07MAR2008 | CK. J.M.B. 5/14/08

Tyco Electronics ©COPYRIGHT 2005
 TYCO ELECTRONICS CORPORATION
 ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG ITEM
 CUST. NO. REV.

TE NUMBER
9-1617751-6

CII PART NUMBER
FCA-210-CW4