

REV. C
DCO 300855

TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED


COIL: @ 25°C
 RESISTANCE _____ CURRENT: 40mA MAX.
 NOMINAL VOLTAGE _____ 115 VAC - 400Hz
 MUST OPERATE _____ 70.0 VAC MAX., 400Hz

 MUST RELEASE _____ 25.0 VAC MAX., 8.0 VAC MIN., 400 Hz

ENVIRONMENT:
 VIBRATION _____ 33 _____ Hz TO _____ 3000 _____ Hz @ _____ 30 _____ g's
 SHOCK _____ 200 _____ g's _____ 6 _____ MS. DURATION
 TEMPERATURE _____ -70 _____ °C TO _____ +125 _____ °C

NOTES: OPERATE TIME 15 mS MAX.
 RELEASE TIME 50 mS MAX.
 CONTACT BOUNCE 1 mS MAX.

CUSTOMER DATA SHEET

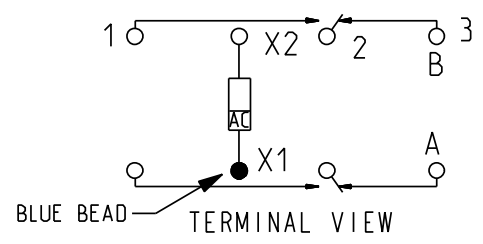

CONTACT RATING: _____
 10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE.
 100,000 OPERATIONS

DR. B.D. 07MAR2008 | CK. J.M.B. 5/14/08

Tyco Electronics ©COPYRIGHT 2005
 TYCO ELECTRONICS CORPORATION
 ALL INTERNATIONAL RIGHTS RESERVED

CUST. _____ CATALOG ITEM _____
 CUST. NO. _____ REV. _____

TE NUMBER
 1617752-9

CII PART NUMBER
 FCA-210-CY8