

REV. C
DCO 300853


TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C
RESISTANCE _____ CURRENT: 40mA MAX.
NOMINAL VOLTAGE 115 VAC - 400Hz
MUST OPERATE 70.0 VAC MAX., 400Hz
MUST RELEASE 25.0 VAC MAX., 8.0 VAC MIN., 400 Hz

ENVIRONMENT:
VIBRATION 33 Hz TO 3000 Hz @ 30 g's
SHOCK 200 g's 6 MS. DURATION
TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE TIME 20 MS MAX.
RELEASE TIME 50 MS MAX.
CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

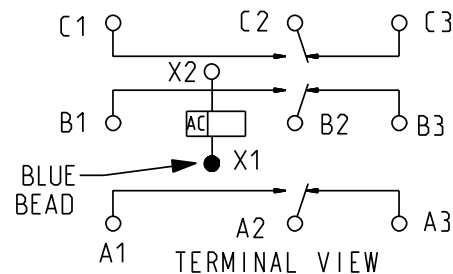

CONTACT RATING: 25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
50,000 OPERATIONS

DR. B.D. 10APR2008 CK. J.M.B. 5/14/08

Tyco Electronics ©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. _____ CATALOG _____
CUST. NO. ---- REV. N/A

TE NUMBER
3-1617753-4

CII PART NUMBER
FCA-325-AV8