

REV. B  
DCO 300859

TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	CURRENT: 40mA MAX.
RESISTANCE _____	
NOMINAL VOLTAGE _____	115 VAC - 50-400 Hz
MUST OPERATE _____	70.0 VAC MAX., 50-400 Hz
MUST RELEASE _____	25.0 VAC MAX., 8.0 VAC MIN., 50-400 Hz


ENVIRONMENT:

VIBRATION	57 Hz TO 3000 Hz @ 20 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES:

OPERATE TIME	20 MS MAX.
RELEASE TIME	50 MS MAX.
CONTACT BOUNCE	1 MS MAX.

CUSTOMER DATA SHEET

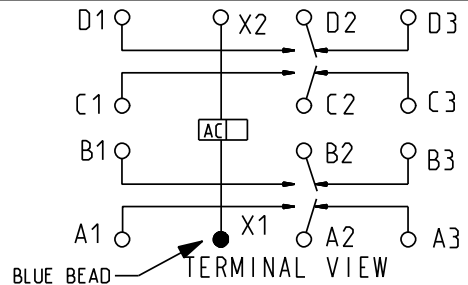

CONTACT RATING:

10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
100,000 OPERATIONS

DR. B.D. 16MAY2008 CK. J.M.B. 5/19/08

**Tyco Electronics** ©COPYRIGHT 2005  
TYCO ELECTRONICS CORPORATION  
ALL INTERNATIONAL RIGHTS RESERVED

CUST. \_\_\_\_\_ CATALOG ITEM \_\_\_\_\_  
CUST. NO. ----- REV. -----

TE NUMBER  
1617756-2

CII PART NUMBER  
FCA-410-CX9