

REV. B  
DCO 300859

TOLERANCES  $\pm .010$ " - UNLESS OTHERWISE SPECIFIED


COIL: @ 25°C	
RESISTANCE	290 OHMS $\pm 10\%$
NOMINAL VOLTAGE	28 VDC
MUST OPERATE	13.5 VDC MAX.
COIL TRANSIENT SUPPRESSION: 42 VDC MAX.	
MUST RELEASE	5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:

VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES: OPERATE, RELEASE 15 MS MAX.  
CONTACT BOUNCE 1 MS MAX.  
CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

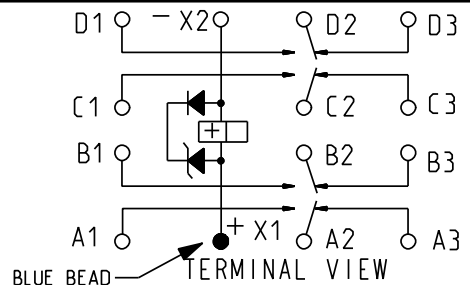

CONTACT RATING:  
10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE  
100,000 OPERATIONS

DR. B.D. 16MAY2008 CK. J.M.B. 5/19/08



©COPYRIGHT 2005  
TYCO ELECTRONICS CORPORATION  
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG ITEM \_\_\_\_\_  
CUST. NO. ---- REV. ----

TE NUMBER  
1617756-5

CII PART NUMBER  
FCA-410-CY4