

REV. A
DCO 301393


TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C
 RESISTANCE _____ CURRENT: 40mA MAX.
 NOMINAL VOLTAGE _____ 115 VAC - 400Hz
 MUST OPERATE _____ 70.0 VAC MAX., 400Hz
 MUST RELEASE _____ 25.0 VAC MAX., 8.0 VAC MIN., 400 Hz

ENVIRONMENT:
 VIBRATION _____ 33 _____ Hz TO _____ 3000 _____ Hz @ _____ 30 _____ g's
 SHOCK _____ 200 _____ g's _____ 6 _____ MS. DURATION
 TEMPERATURE _____ -70 _____ °C TO _____ +125 _____ °C

NOTES: OPERATE TIME 20 MS MAX.
 RELEASE TIME 50 MS MAX.
 CONTACT BOUNCE 1 MS MAX.
 AUX: CONTACT BOUNCE 4 MS MAX.

CUSTOMER DATA SHEET

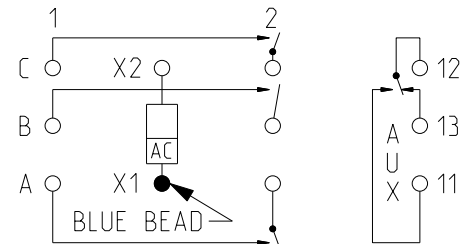

TERMINAL VIEW

CONTACT RATING: MAIN: 25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE 50,000 OPERATIONS.
 AUX: 2 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE 50,000 OPERATIONS

DR. R.F. 08JUN2011 CK. M.B. 08JUN2011



CUST. _____ CATALOG _____
 CUST. NO. _____ REV. N/A

TE NUMBER

CII PART NUMBER

FCAC-325-AV8