

REV. A
DCO 301393


TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C
 RESISTANCE _____ 290 OHMS ±10%
 NOMINAL VOLTAGE _____ 28 VDC
 MUST OPERATE _____ 13.5 VDC MAX.
 _____ TRANSIENT SUPPRESSION - 42 VDC MAX.
 MUST RELEASE _____ 6.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:
 VIBRATION _____ 33 _____ Hz TO _____ 3000 _____ Hz @ _____ 30 _____ g's
 SHOCK _____ 200 _____ g's _____ 6 _____ MS. DURATION
 TEMPERATURE _____ -70 _____ °C TO _____ +125 _____ °C

NOTES: _____ OPERATE, RELEASE 15 MS MAX.
 _____ CONTACT BOUNCE 1 MS MAX.
 _____ CONTACT BREAK BOUNCE 0.1 MS MAX.
 _____ AUX: CONTACT BOUNCE 4MS MAX.

CUSTOMER DATA SHEET

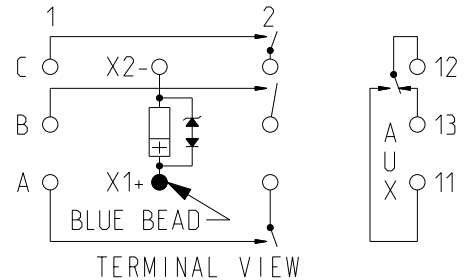

CONTACT RATING: _____ MAIN: 25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE 50,000 OPERATIONS.
 _____ AUX: 2 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE 50,000 OPERATIONS

DR. R.F. 08JUN2011 | CK. M.B. 08JUN2011



CUST. _____ CATALOG
 CUST. NO. _____ REV. N/A

TE NUMBER
1-1617801-8

CII PART NUMBER
FCAC-325-AY4