


REV. A
DCO 300783

TOLERANCES $\pm .010$ " - UNLESS OTHERWISE SPECIFIED

| | |
|-----------------|-----------------------------|
| COIL: @ 25°C | |
| RESISTANCE | 95 OHMS $\pm 10\%$ |
| NOMINAL VOLTAGE | 12 VDC |
| MUST OPERATE | 6.5 VDC MAX. |
| MUST RELEASE | 3.3 VDC MAX., 0.75 VDC MIN. |

CUSTOMER DATA SHEET

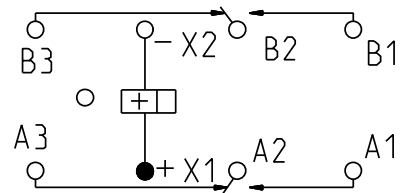

TERMINAL VIEW

| | |
|-----------------------------------|---------------------------|
| ENVIRONMENT: | |
| VIBRATION | 70 Hz TO 3000 Hz @ 30 g's |
| SHOCK | 200 g's 6 MS. DURATION |
| TEMPERATURE | -70 °C TO +125 °C |
| NOTES: OPERATE, RELEASE 5 MS MAX. | |
| CONTACT BOUNCE 1 MS MAX. | |

CONTACT RATING: LOW LEVEL
TO 5 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE,
100,000 OPERATIONS

DR. B.D. 14MAR2008 CK. J.M.B. 3/17/08

Tyco Electronics ©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG ITEM _____
CUST. NO. _____ REV. _____

TE NUMBER
6-1617758-7

CII PART NUMBER
FCB-205-AY2