


REV. A  
DCO 300783

TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	20 OHMS ±10%
NOMINAL VOLTAGE	6 VDC
MUST OPERATE	3.30 VDC MAX.
MUST RELEASE	1.60 VDC MAX., 0.50 VDC MIN.

CUSTOMER DATA SHEET

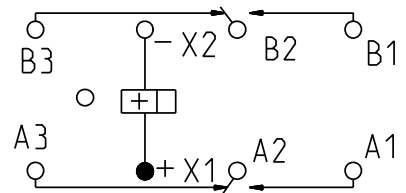

TERMINAL VIEW

ENVIRONMENT:	
VIBRATION	70 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C
NOTES: OPERATE, RELEASE 5 MS MAX. CONTACT BOUNCE 1 MS MAX.	

CONTACT RATING: LOW LEVEL  
TO 5 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE,  
100,000 OPERATIONS

DR. B.D. 11MAR2008 CK. J.M.B. 3/17/08

**Tyco Electronics** ©COPYRIGHT 2005  
TYCO ELECTRONICS CORPORATION  
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG ITEM  
CUST. NO. REV.

TE NUMBER  
7-1617758-2

CII PART NUMBER  
FCB-205-BY1