

REV. B  
DCO 300825

TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED


COIL: @ 25°C	
RESISTANCE	400 OHMS ±10%
NOMINAL VOLTAGE	28 VDC
MUST OPERATE	13.5 VDC MAX.
MUST RELEASE	5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:

VIBRATION	70 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES: OPERATE, RELEASE 6 MS MAX.  
CONTACT STABILIZATION 2.5 MS MAX.  
CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

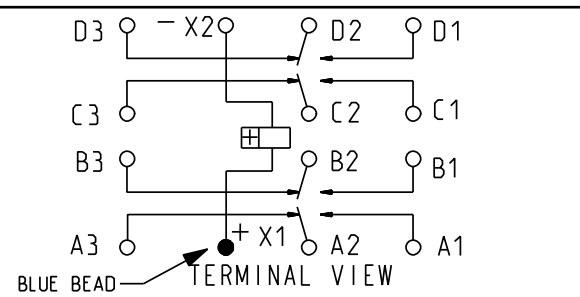

CONTACT RATING:	LOW LEVEL
	5 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
	100,000 OPERATIONS

DR. B.D. 25APR2008 CK. 5/9/08 J.M.B.

**Tyco Electronics** ©COPYRIGHT 2005  
TYCO ELECTRONICS CORPORATION  
ALL INTERNATIONAL RIGHTS RESERVED

CUST. M83536/5-022M  
CUST. NO. ---- REV. ---

TE NUMBER  
6-1617760-8

CII PART NUMBER  
FCB-405-0522M