
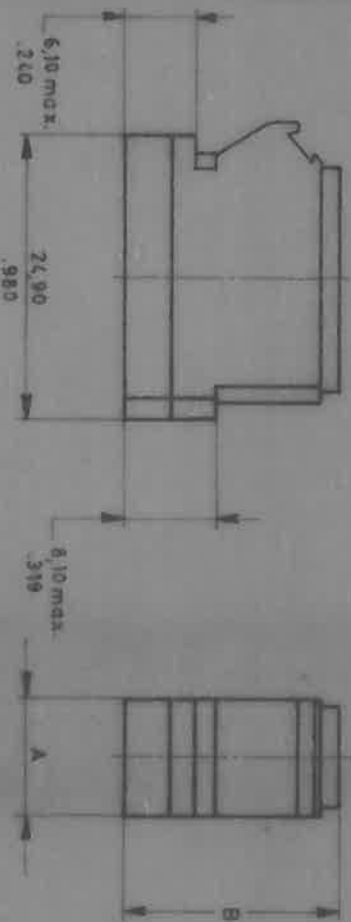


RENSEIGNEMENTS SUR LES CONTACTS

| RÉFÉRENCE   | JAUGE | JAUGE DU CABLE(AWG) | SECTION DES CABLES(mm <sup>2</sup> ) | ÉTANCHÉITÉ ASSURÉE POUR |                     |                      | C +0,08             |      | D max. |      | E max. |      | Poids |        |      |
|-------------|-------|---------------------|--------------------------------------|-------------------------|---------------------|----------------------|---------------------|------|--------|------|--------|------|-------|--------|------|
|             |       |                     |                                      | ∅ extér. min.<br>in.    | ∅ extér. min.<br>mm | ∅ extér. max.<br>in. | ∅ extér. max.<br>mm | in.  | mm     | in.  | mm     | lbs  | g.    |        |      |
| 1000.50.56  | 22    | 26.24.22            | 0.18 - 0.30                          | .033                    | 0.84                | .049                 | 1.25                | .057 | 1.44   | .320 | 8.32   | .155 | 3.95  | .00013 | 0.06 |
| 1841.1.5620 | 20    | 24.22.20            | 0.21 - 0.93                          | .040                    | 1.05                | .083                 | 2.10                | .100 | 2.54   | .288 | 7.31   | .165 | 4.20  | .00287 | 0.13 |
| 1841.1.5615 | 16    | 20.18.16            | 0.60 - 1.34                          | .068                    | 1.75                | .103                 | 2.50                | .130 | 3.30   | .388 | 9.85   | .250 | 6.35  | .00685 | 0.31 |
| 1841.1.5612 | 12    | 14.12               | 1.91 - 3.39                          | .106                    | 2.70                | .158                 | 4.00                | .187 | 4.75   | .428 | 10.85  | .252 | 6.40  | .0165  | 0.75 |

| RÉFÉRENCE      | A max. |       | B max. |       | Poids |      |
|----------------|--------|-------|--------|-------|-------|------|
|                | in.    | mm    | in.    | mm    | lbs   | g.   |
| FMJ 11E.22.*** | .396   | 10.05 | .806   | 20.47 | .0143 | 6.5  |
| FMJ 11E.20.*** | .386   | 10.05 | .765   | 19.42 | .0118 | 6.7  |
| FMJ 11E.16.*** | .475   | 12.05 | .765   | 19.42 | .0172 | 7.8  |
| FMJ 11E.12.*** | .583   | 15.05 | .947   | 24.05 | .0224 | 10.2 |

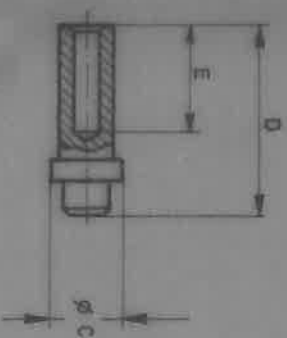

Compagnie DEUTSCH

MODULES DE JONCTION ET CONTACTS

Tailles 22, 20, 16, 12

Visas

