



KAPTON LABELS OVERVIEW

SERIES	PART NO.	DESCRIPTION	MATERIAL	TTDS
T1K	E88300-000	T1K-044033-10-9	KP228, Kapton white gloss (0,063 mm), Acrylic adhesive	TTDS-034
T2K	C23724-000	T2K-044033-10-9	KP842, Kapton white gloss (0,118 mm), Acrylic adhesive	TTDS-035
TSK	D11494-000	TSK-044033-10-9	KP7251, Kapton white gloss (0,118 mm), Acrylic adhesive	TTDS-085

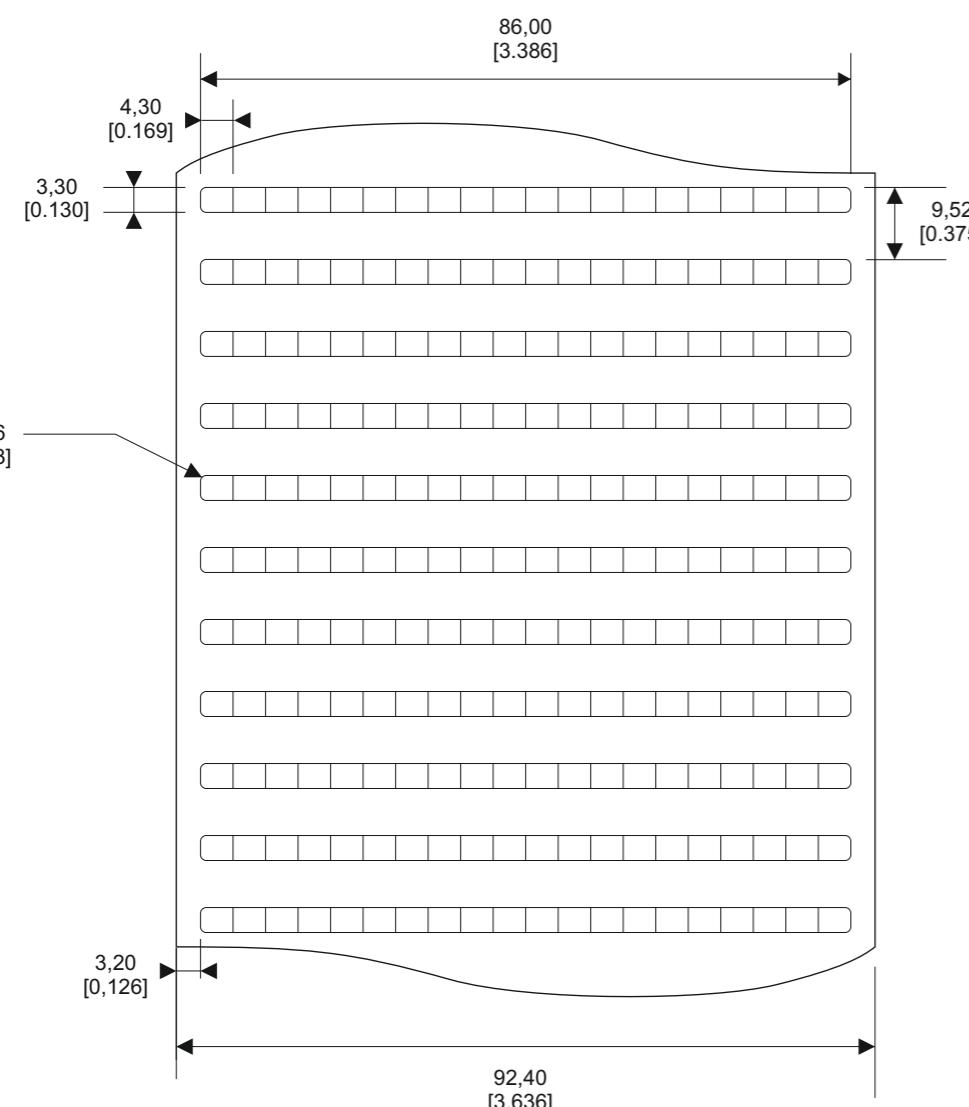

All dimensions in mm [inch]

labels are centered on the liner as long as not declared separately

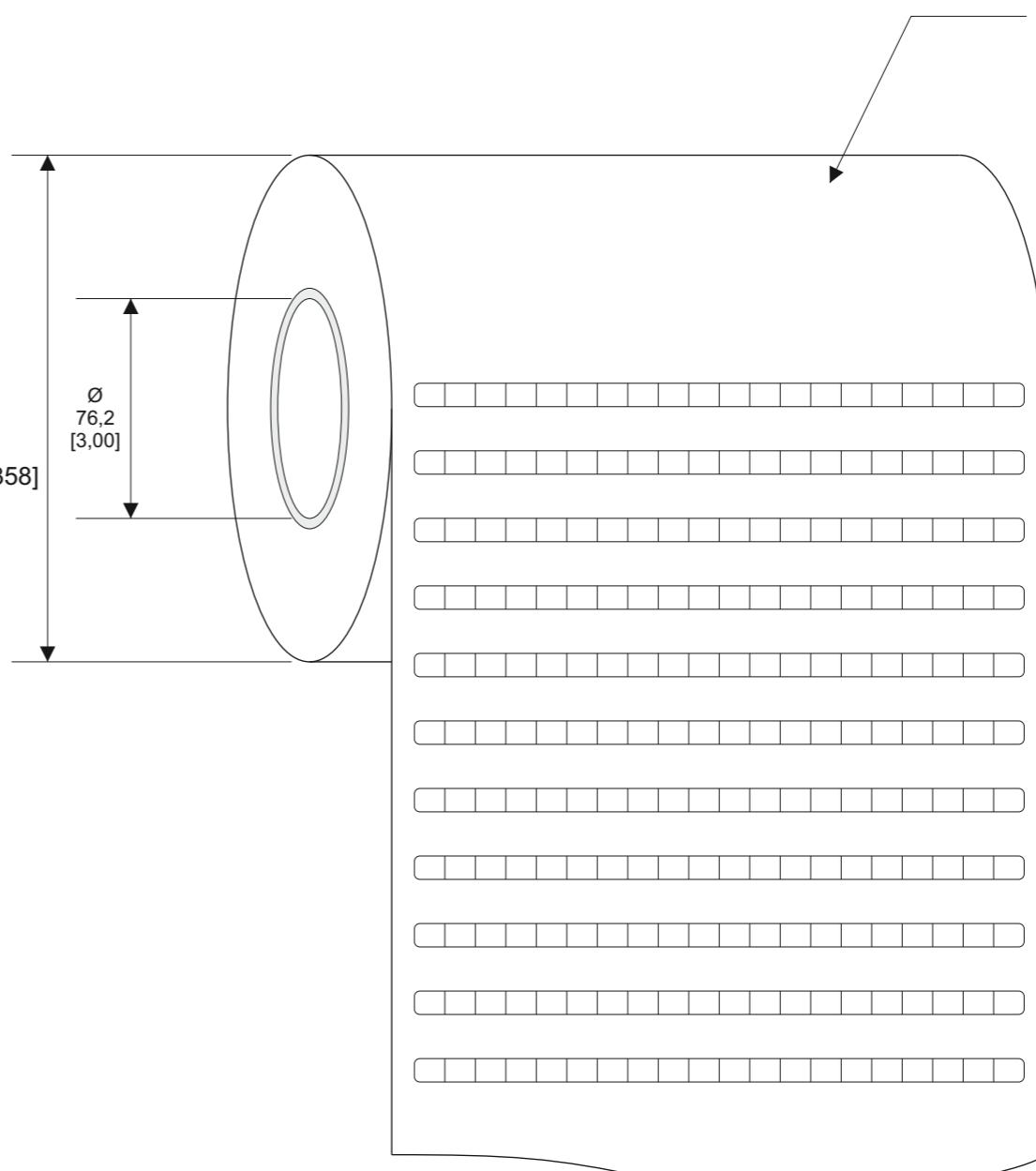

Quantity per roll:	10.000 PCs
Labels across:	20
Winding:	outside
length of roll:	4,76 m

LABEL BUILD DETAILS		TOLERANCES mm [INCH]	THIS DRAWING IS A CONTROLLED DOCUMENT		DWN S. Iser / 01.04.2020	DATE	 TE connectivity	TE Connectivity			
	SUBSTRATE	LABEL HEIGHT: ±0,3 [.012]			CHK S. Iser / 01.04.2020	DATE					
	ADHESIVE	LABEL WIDTH: ±0,3 [.012]			APVD S. Iser / 01.04.2020	DATE	Name				
	LINER	WEB WIDTH: ±0,8 [.031]			PRODUCT SPEC	DATE	Kapton Label Size „044033"				
VERTICAL REPEAT: ±0,8 [.031]*					APPLICATION SPEC	DATE					
HORIZONTAL REPEAT: ±0,8 [.031]*					WEIGHT T1K: 0,002 g T2K/TSK: 0,003g		SIZE A3	CAGE CODE C2290			
PRINT POSITIONING: ±0,8 [.031]*					MATERIAL	FINISH					
LEFT MARGIN: ±0,4 [.016]					SEE TABLE	GLOSS UNPRINTED MATT PRINTED	DRAWING NO C-KAPTON	RESTRICTED TO			
QUANTITY: -0% +2%					CUSTOMER DRAWING						
*NON ACCUMULATING								SHEET 1 of 1			
								REV A1			