



REVISIONS

P	LTR	DESCRIPTION	DATE	DWN	APVD
B		RELEASED AS PER ECO-17-009529	03JUL2017	KH	MP

a) Part as supplied.

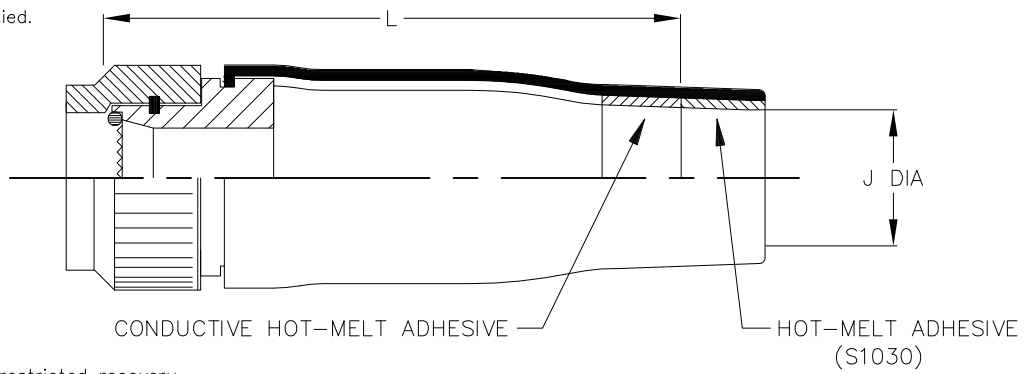

b) Part after unrestricted recovery.

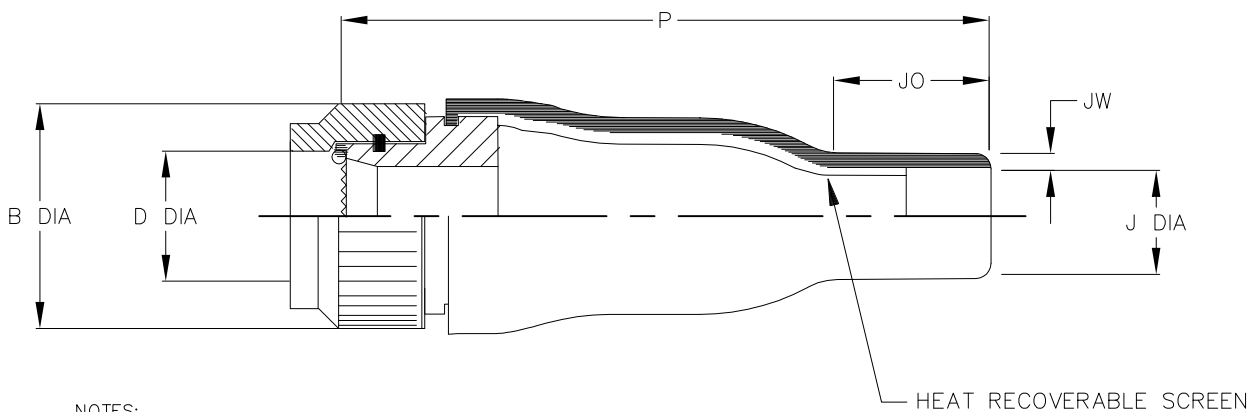

NOTES:

Raychem Connector Code: 18C
 Connector Series: MIL-C-5015 (MS3100)
 Adaptor Series: 218M7**-62-C12-K-NS (Bright)
 Stainless steel to BS970 302S25, 303S31, 316S11, 316S31
 Or SAE AMS-QQ-S-763 or MIL-T-8606 347
 Electroless Nickel per SAE-AMS-C-26074, Class 1, Grade B
 Or ASTM B-733, SC2, Type I, Class 5
 Moulded Part Material: -100C (Black); Polyolefin/Silver Composites, semi-flexible
 ZEROHAL™ Low fire hazard

Kits to include cleaning tissue, 1 piece 100 grit emery cloth & packing piece.
 Kit to be used in conjunction with installation guide for straight assemblies.

Dimensions in mm [inches for reference]

Part No.	Shell Size	B DIA MAX	D DIA MIN	J		P ±10% b	L REF a	JO REF b	JW ±30% b
				MIN a	MAX b				
KTKK4632	16	31.2 [1.23]	18.8 [.74]	17 [.67]	8.5 [.33]	100 [3.94]	91 [3.58]	25 [.98]	1.0 [.04]

RELEASED FOR PUBLICATION

ALL RIGHTS RESERVED.

THIS DRAWING IS UNPUBLISHED.

© COPYRIGHT 2016 By TE Connectivity

DIMENSIONS: mm [INCHES]	DWN K. HOTAL	14OCT2016	MATERIAL	SEE NOTES	FINISH	SEE NOTES
	CHK N. NAGAR	14OCT2016				
TOLERANCES UNLESS OTHERWISE SPECIFIED:	APVD M. POPE	14OCT2016				
0 PLC ± -	PRODUCT SPEC	NAME ADAPTOR ASSEMBLY				
1 PLC ± -	—					
2 PLC ± -	APPLICATION SPEC	SIZE CAGE CODE DRAWING NO RESTRICTED TO				
3 PLC ± -	—					A4 00779 C-KTKK4632 —
4 PLC ± -	WEIGHT	CUSTOMER DRAWING SCALE DNS SHEET 1 OF 1 REV B				
ANGLES ± -	—					

