
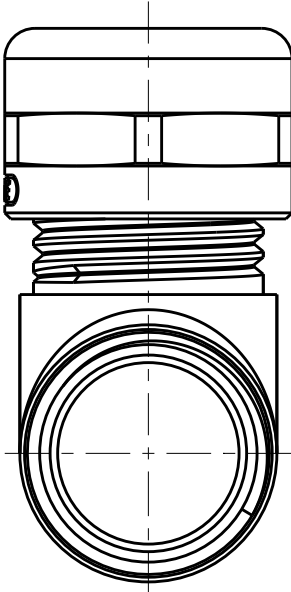
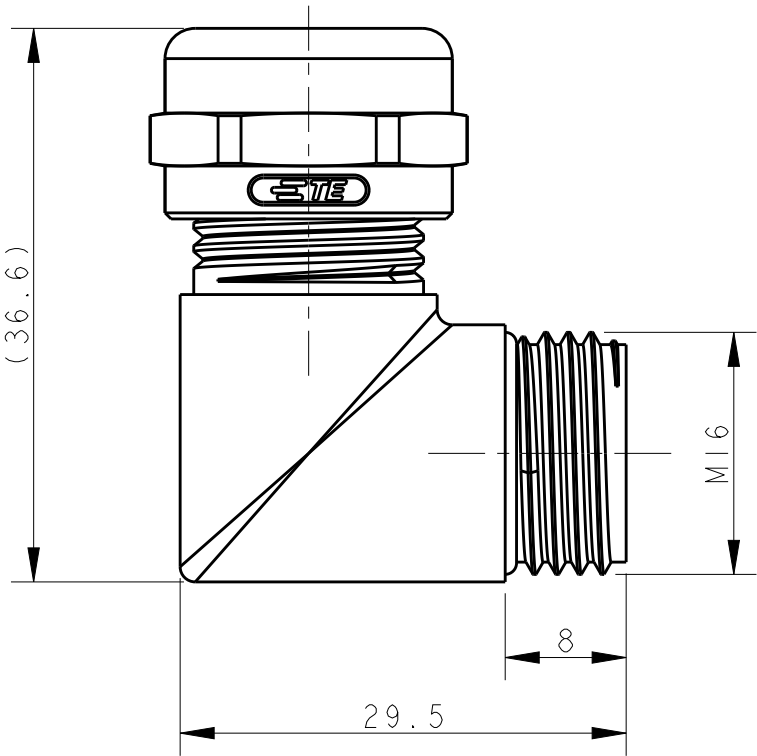
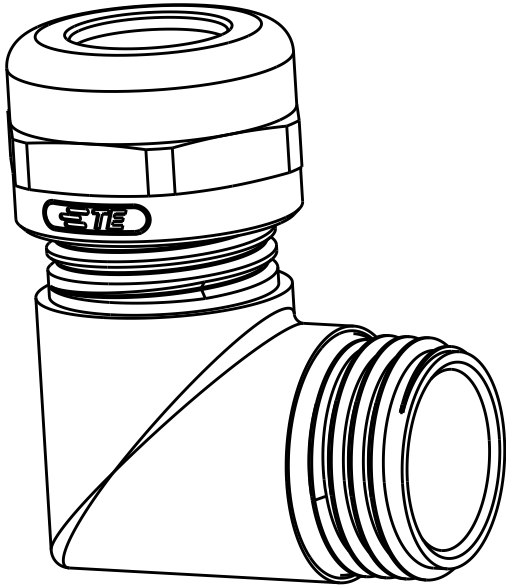


 
REVISIONS					
P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	INITIAL RELEASE	19MAY2016	DL	CW

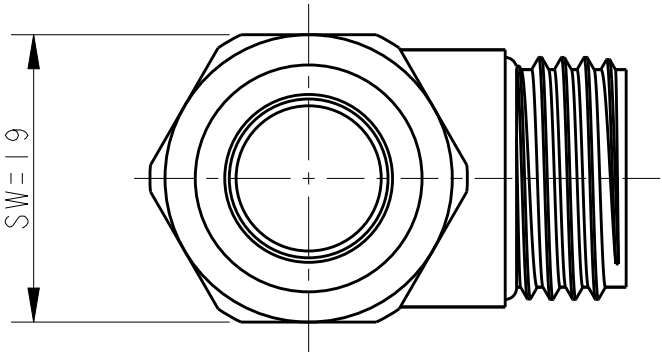

NOTES:
1. TECHNICAL CHARACTERISTICS:
SHELL MATERIAL: BRASS WITH Ni PLATED
PINCH RING MATERIAL: TPE
SEAL MATERIAL: NBR
PROTECTION DEGREE: IP68 (MATED)
WIRE RANGE: Ø8~Ø9.5mm

注释:
1. 技术参数:
主体材料: 铜镀镍
夹紧件材料: TPE
密封材料: NBR
防护等级: IP68 (配合)
夹线范围: Ø8~Ø9.5mm

T3265161611-000	STUD-16-M	ANGLED METAL CABLE GLAND, M16 金属直角变径接头M16
PART NUMBER 料 号	PART DESCRIPTION 描 述	

THIS DRAWING IS A CONTROLLED DOCUMENT.		DWN DAVID LI 19MAY2016	TE Connectivity						
DIMENSIONS: mm	TOLERANCES UNLESS OTHERWISE SPECIFIED:	CHK CHRIS WANG 19MAY2016							
		APVD XIANG XU 19MAY2016							
		PRODUCT SPEC	NAME ANGLED METAL CABLE GLANDS STUD-16-M						
		-							
		APPLICATION SPEC							
		-							
MATERIAL	FINISH	WEIGHT	SIZE	CAGE CODE	DRAWING NO	RESTRICTED TO			
-	-	-	A3	-	C-T3265161611000	-			
-	-	CUSTOMER DRAWING				SCALE	SHEET	OF	REV
					2:1	1	1	A	