



REVISIONS					
P	LTR	DESCRIPTION	DATE	DWN	APVD
A1		NEW DRAWING FORMAT	12MAY2020	GK	DB

### LABEL AND LINER DESIGN

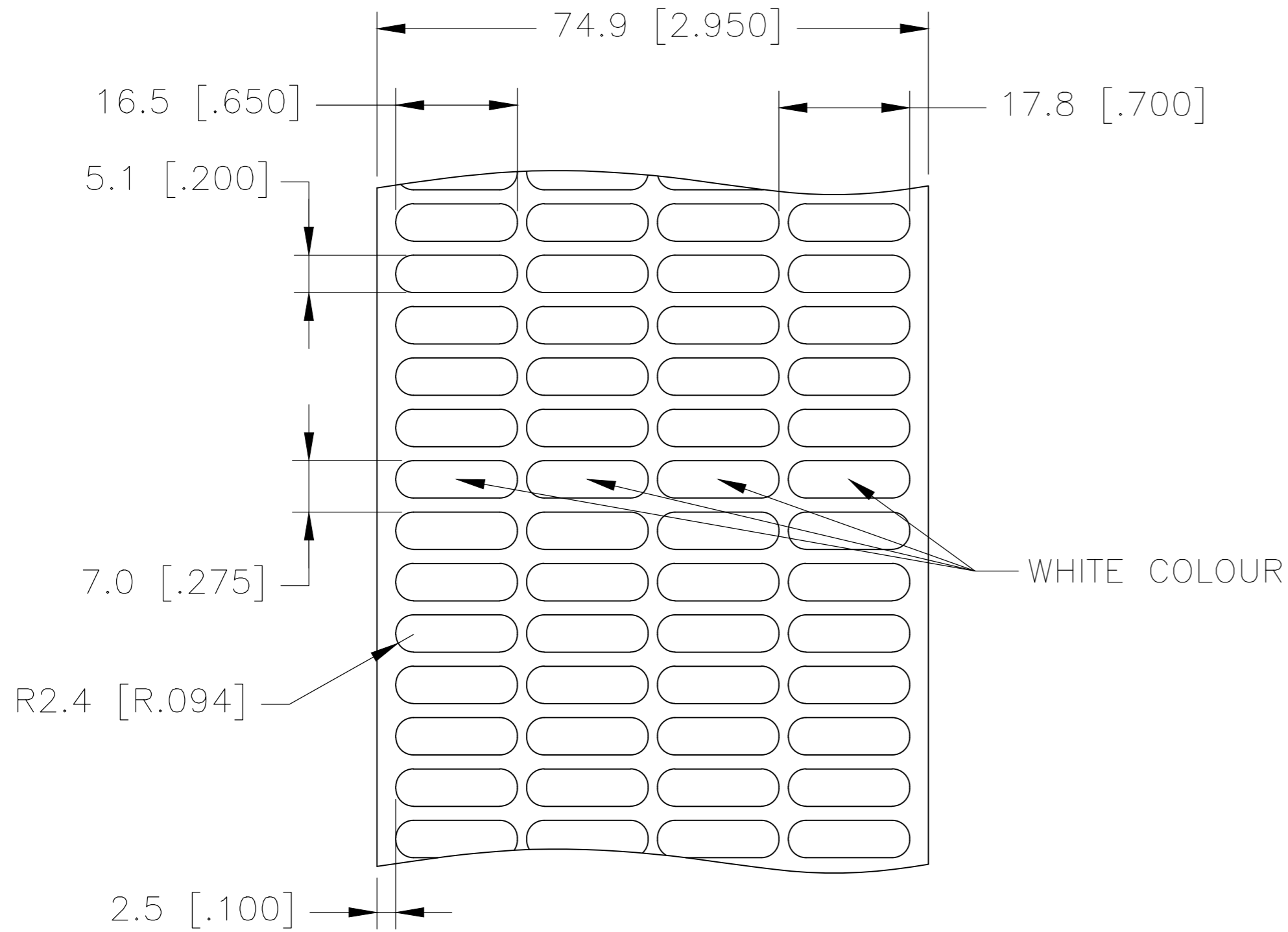

### PRESENTATION

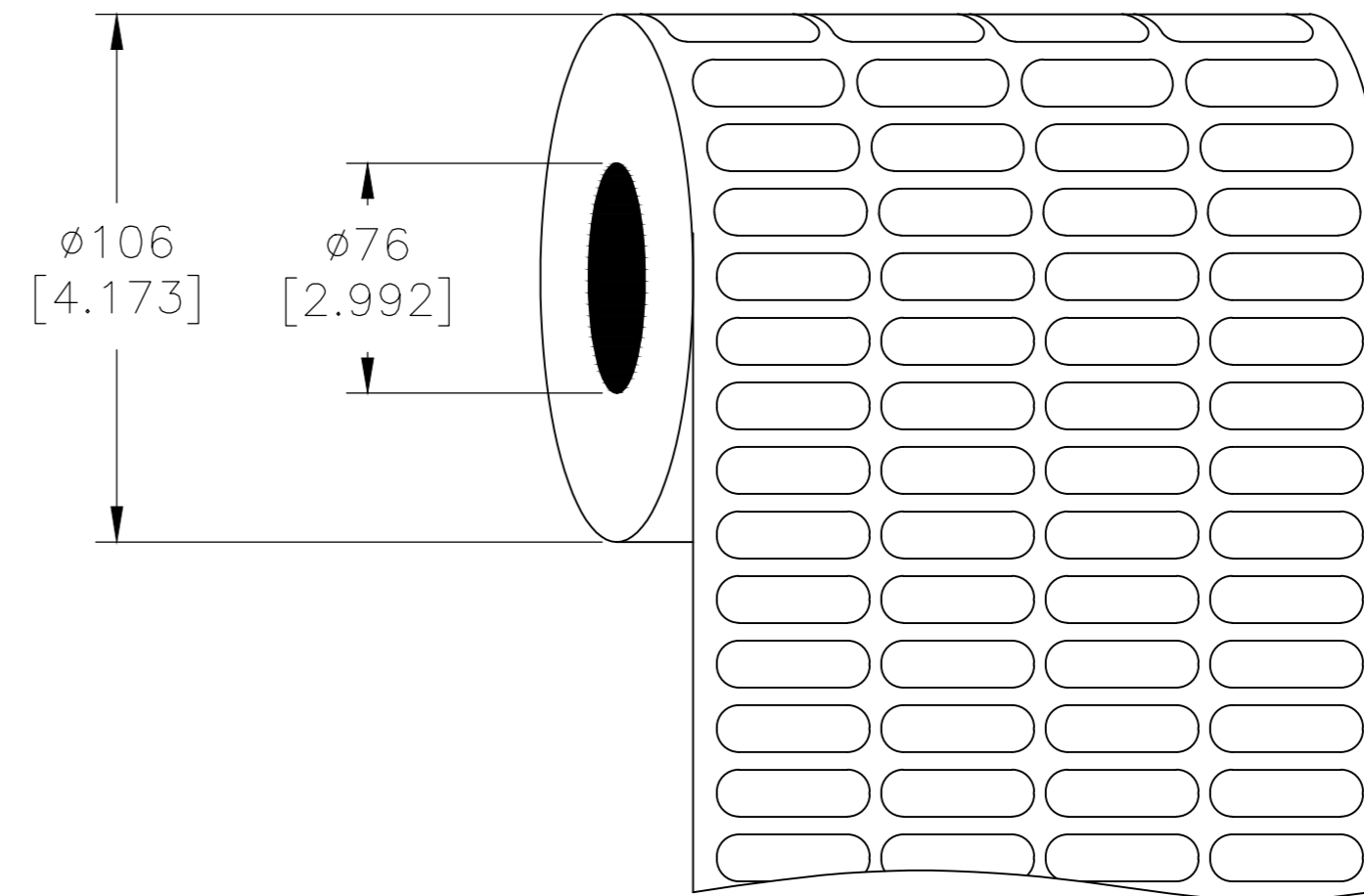

**OUTSIDE WOUND  
LABEL ACROSS: 4  
PER ROLL QTY: 10,000**

All dimensions in mm [Inch]

**TE PN: F86631-000**

MATERIAL	POLYVINYL FLUORIDE (TEDLAR®)	
ADHESIVE TYPE	PERMANENT ACRYLIC	
LINEAR	BROWN KRAFT	
DWN	12MAY2020	
CHK	GOPALAKRISHNA HV	
APVD	D.BURGAT	
PRODUCT SPEC	12MAY2020	
NAME	TEDLAR® LABEL - WHITE - 4 ACCROSS 16.5mm x 5.1mm (0.65inch x 0.2inch)	
APPLICATION SPEC	TTDS-005	
WEIGHT	0.011g	RESTRICTED TO
CUSTOMER DRAWING	A2 FB1U7 C=TTVF065020WE10	
SCALE	NTS	SHEET 1 OF 1
REV	A1	

TOLERANCES mm [INCH]		THIS DRAWING IS A CONTROLLED DOCUMENT.	
LABEL HEIGHT:	±0.3 [.012]	DIMENSIONS:	TOLERANCES UNLESS OTHERWISE SPECIFIED
LABEL WIDTH:	±0.3 [.012]	mm [INCHES]	
WEB WIDTH:	±0.8 [.031]		
VERTICAL REPEAT:	±0.8 [.031]*		
HORIZONTAL REPEAT:	±0.8 [.031]*		
PRINT POSITIONING:	±0.8 [.031]*		
LEFT MARGIN:	±0.4 [.016]		
QUANTITY:	-0 % +2 %		
*NON ACCUMULATING			
MATERIAL	SEE TABLE	FINISH	GLOSS