



REVISIONS					
P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	INITIAL RELEASE	18JUL2017	GK	AK
	A1	UPDATED COLOR CODE REQUIREMENTS	21AUG2017	GK	KM

LABEL AND LINER DESIGN

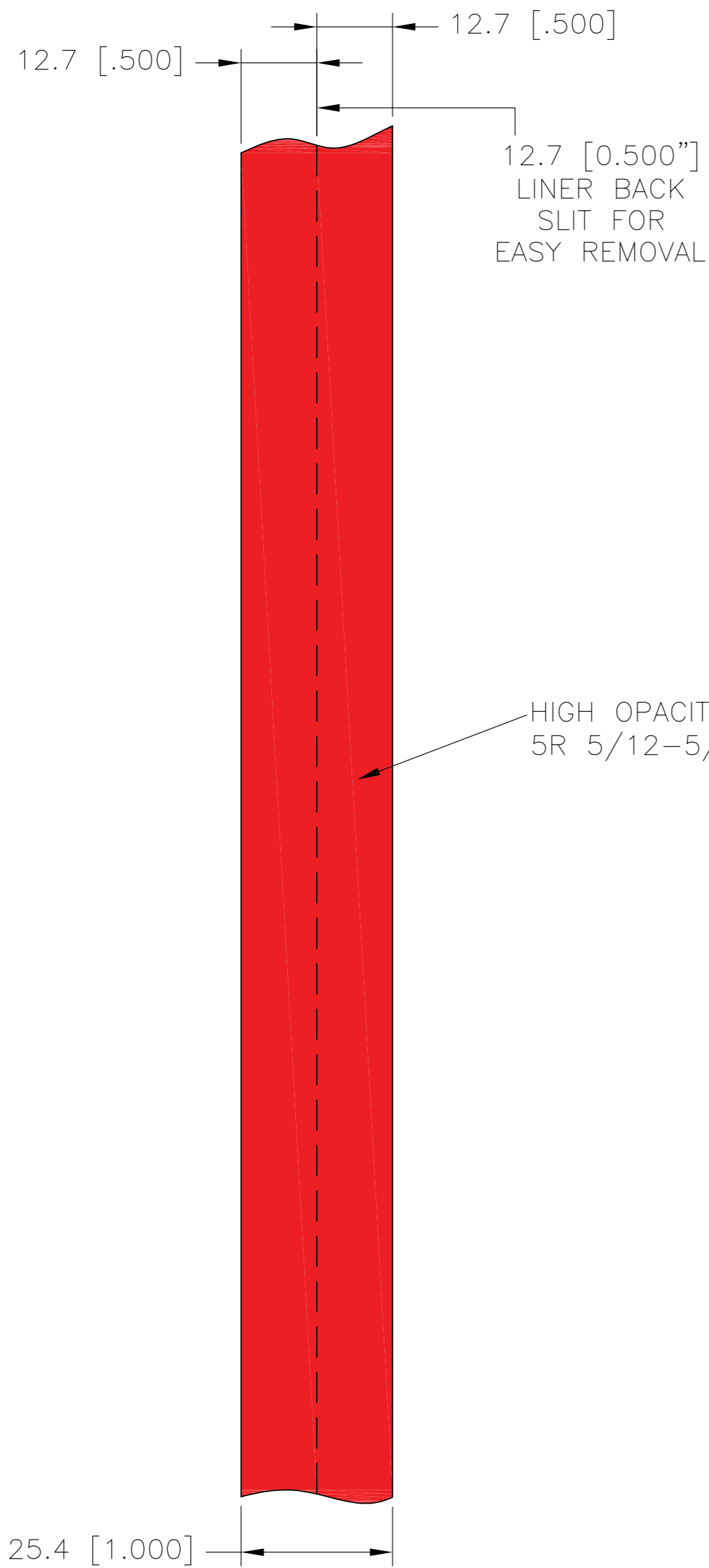

PRESENTATION

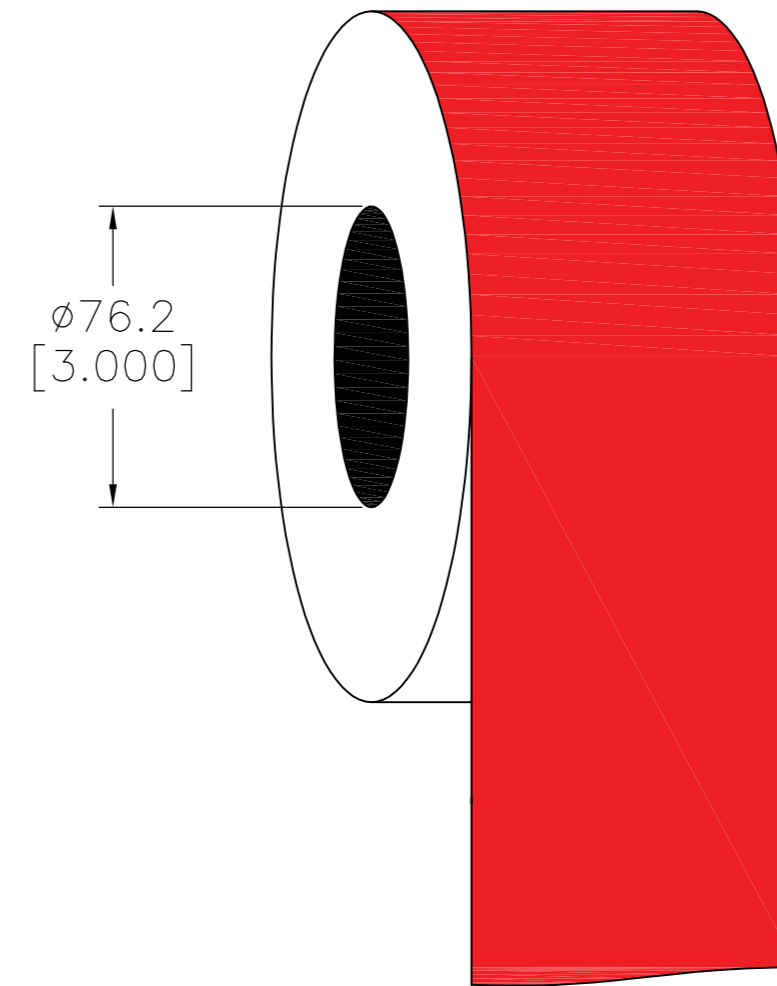

**OUTSIDE WOUND
 LABEL ACROSS: 1
 PER ROLL QTY: 30.48m / 100 feet**

All dimensions in mm [Inch]

TE PN: 104438-000

TOLERANCES mm [INCH]	
LABEL HEIGHT:	±0.3 [.012]
LABEL WIDTH:	±0.3 [.012]
WEB WIDTH:	±0.8 [.031]
VERTICAL REPEAT:	±0.8 [.031]*
HORIZONTAL REPEAT:	±0.8 [.031]*
PRINT POSITIONING:	±0.8 [.031]*
LEFT MARGIN:	±0.4 [.016]
QUANTITY:	-0 % +2 %
*NON ACCUMULATING	

THIS DRAWING IS A CONTROLLED DOCUMENT.	
DIMENSIONS: mm [INCHES]	TOLERANCES UNLESS OTHERWISE SPECIFIED:
	0 PLC ±
	1 PLC ± -
	2 PLC ± -
	3 PLC ± -
	4 PLC ± -
	ANGLES ± -
MATERIAL SEE TABLE	FINISH SATIN

MATERIAL ADHESIVE TYPE LINEAR		TEDLAR PERMANENT ACRYLIC BROWN KRAFT	
DWN GOPALAKRISHNA HV 18JUL2017	CHK ALAN KEAN 18JUL2017	TE Connectivity	
APVD ALAN KEAN 18JUL2017	PRODUCT SPEC TTDS-005	NAME TEDLAR LABEL – RED 25.4mm x 30.4m (1inch x 100ft)	
APPLICATION SPEC	WEIGHT 335g	SIZE A2	CAGE CODE 00779
CUSTOMER DRAWING	SCALE NTS	DRAWING NO TTVF100RD-100	RESTRICTED TO -
		SHEET 1 of 1	REV A1