



REVISIONS					
P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	NEW DRAWING	08MAY2020	GK	DB

LABEL AND LINER DESIGN

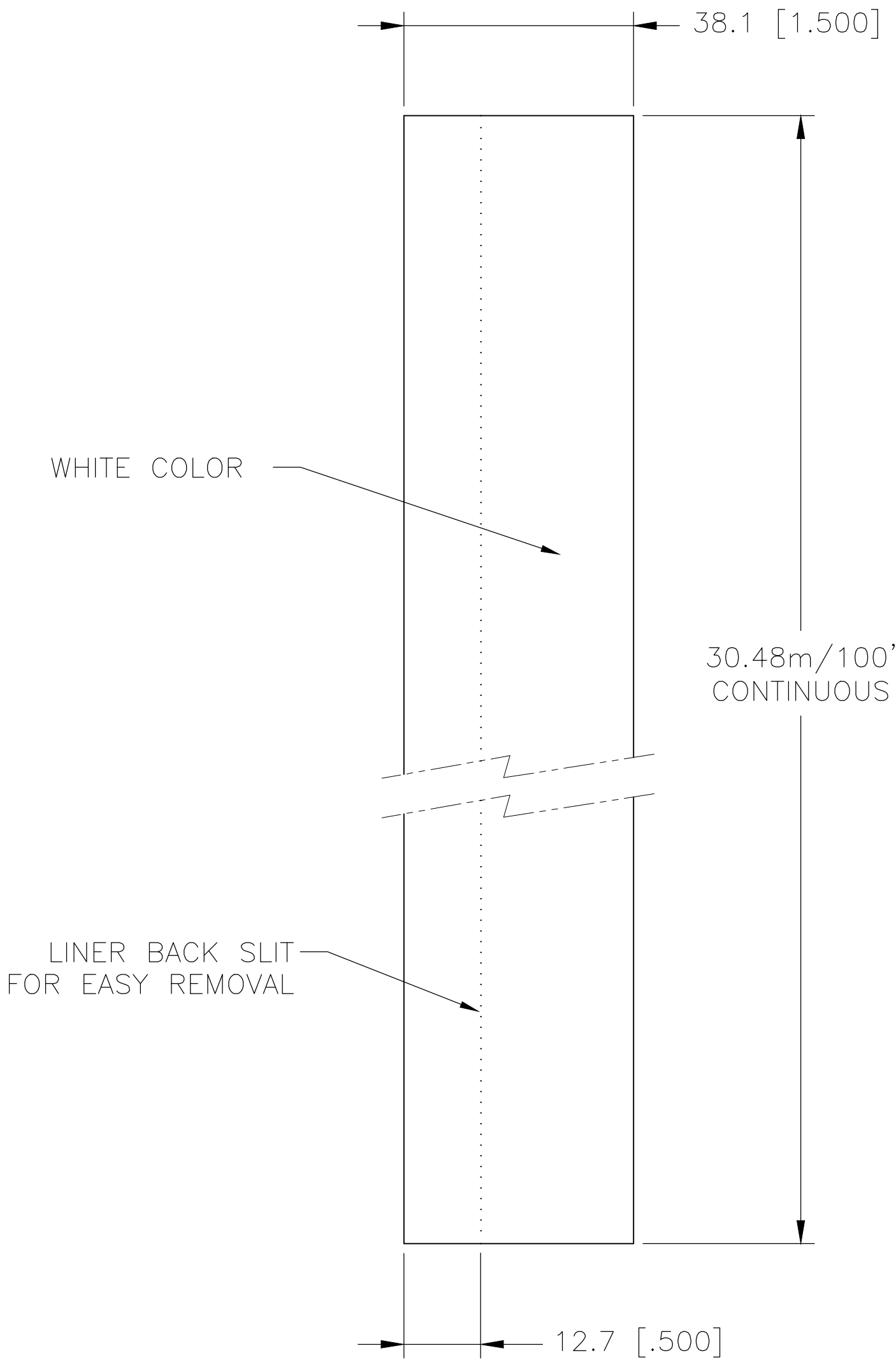

PRESENTATION

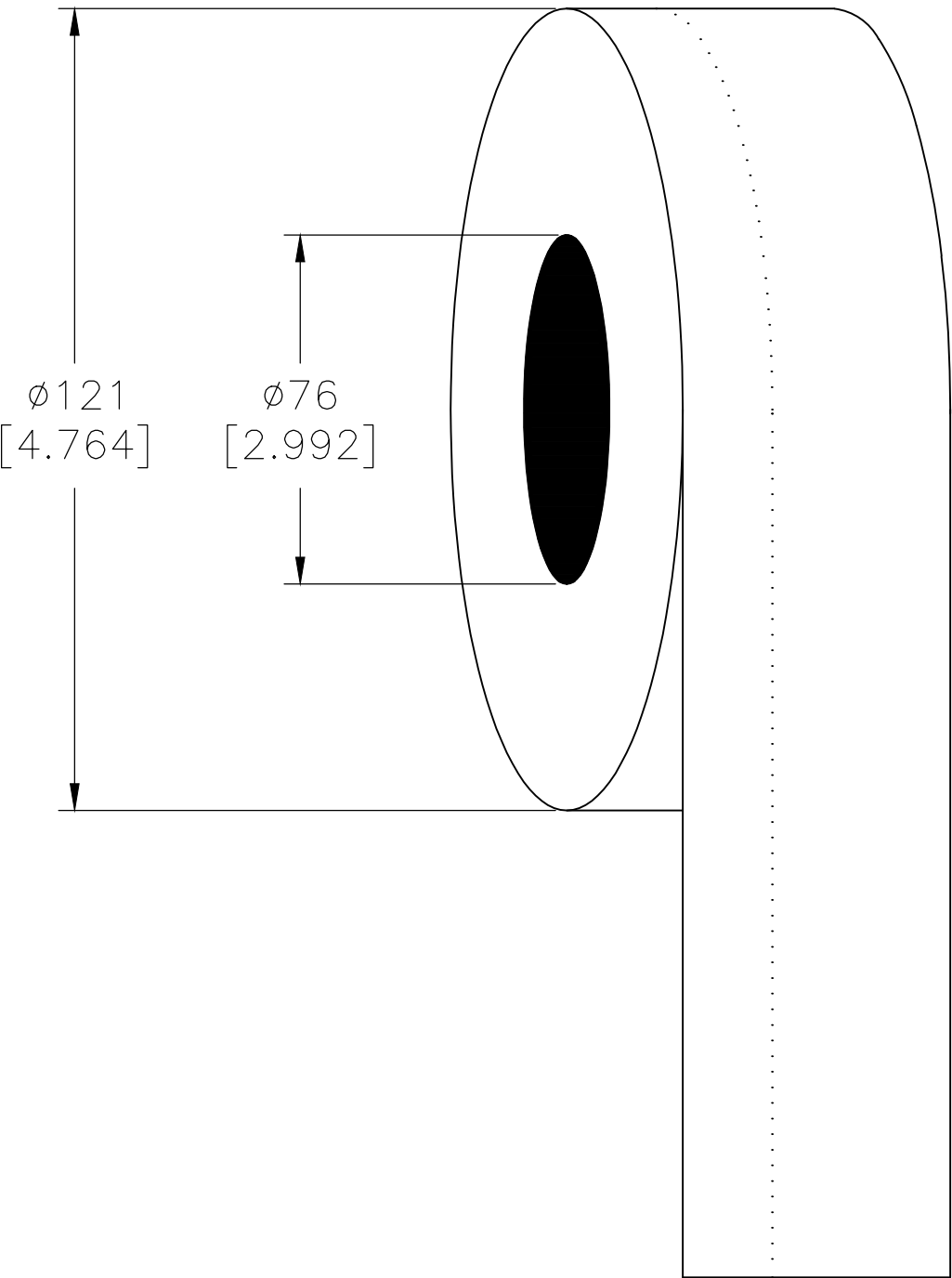

All dimensions in mm [Inch]

TE PN: 335276-000

OUTSIDE WOUND (BACK SLIT LEFT)
LABEL ACROSS: 1
PER ROLL QTY: 30.48m / 100 feet

TOLERANCES mm [INCH]	
LABEL HEIGHT:	±0.3 [.012]
LABEL WIDTH:	±0.3 [.012]
WEB WIDTH:	±0.8 [.031]
VERTICAL REPEAT:	±0.8 [.031]*
HORIZONTAL REPEAT:	±0.8 [.031]*
PRINT POSITIONING:	±0.8 [.031]*
LEFT MARGIN:	±0.4 [.016]
QUANTITY:	-0 % +2 %
*NON ACCUMULATING	

THIS DRAWING IS A CONTROLLED DOCUMENT.	
DIMENSIONS: mm [INCHES]	TOLERANCES UNLESS OTHERWISE SPECIFIED:
	0 PLC ± 1 PLC ± 2 PLC ± 3 PLC ± 4 PLC ± ANGLES ±
MATERIAL SEE TABLE	FINISH GLOSS

MATERIAL		POLYVINYL FLUORIDE (TEDLAR®)				
ADHESIVE TYPE		PERMANENT ACRYLIC				
LINEAR		BROWN KRAFT				
DWN GOPALAKRISHNA HV CHK D.BURGAT APVD D.BURGAT PRODUCT SPEC TTDS-005 APPLICATION SPEC — WEIGHT 159g	12MAY2020 12MAY2020 12MAY2020	TE Connectivity TEDLAR® LABEL – WHITE – CONTINUOUS 38.1mm x 30.4m (1.5inch x 100ft) —			NAME	
		SIZE	CAGE CODE	DRAWING NO	RESTRICTED TO	
A2		FB1U7	C=TTVF150WE-100		—	
CUSTOMER DRAWING			SCALE	NTS	SHEET 1 of 1	REV A