





# Engineering Product Design

<b>Product Construction</b> 12 Conductor Cable Jacketed	<b>Controlled Customer Copy</b> B.W.B. GERMANY	<b>Product Description</b> <b>VG 95218 T027 B015</b>	<b>Rev</b> 2
<b>Designer</b> <i>John Ribbons</i>	<b>Date</b> 01/10/2019	<b>Product Manager</b> <i>Mark Johnstone</i>	<b>Date</b> 01/10/2019

## Component Identification

## Cross-Section

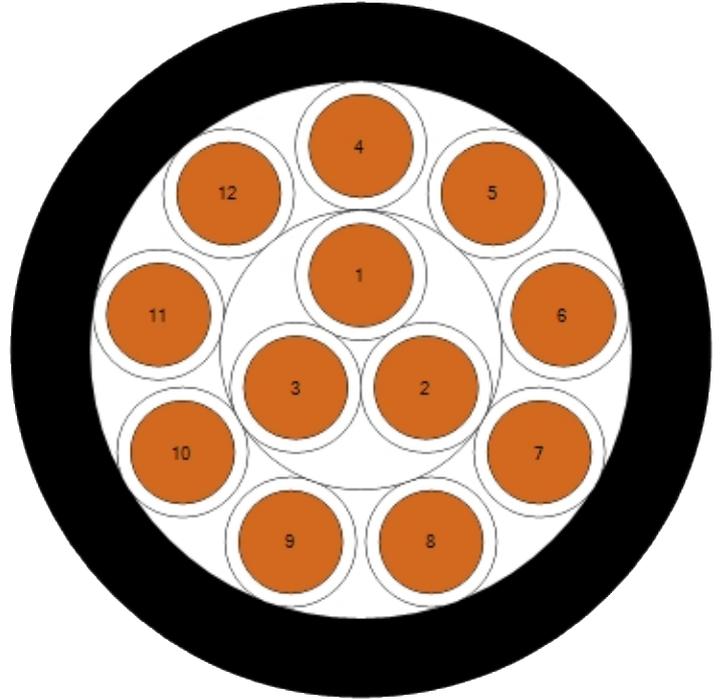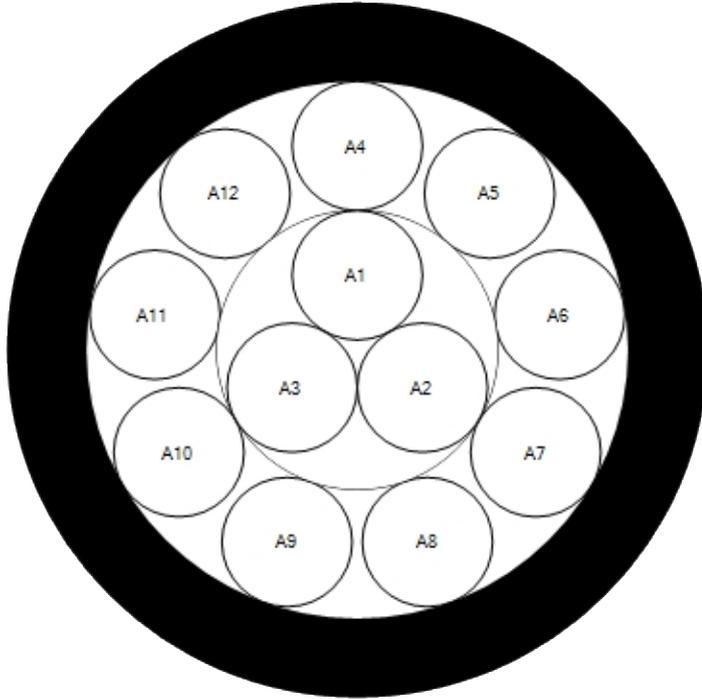

## Components

ID	Type	Quantity	Part Description
A	Wire	12	VG 95218 T020 A007

*(Components refer to issue in effect at date of issue of this EPD)*

## Component Identification

Key	Wire/Core Colour(s)	Wire/Core Number(s)	Jacket/Wrap Colour(s)	Jacket/Wrap Number
A1	9	1		
A2	9	2		
A3	9	3		
A4	9	4		
A5	9	5		
A6	9	6		
A7	9	7		
A8	9	8		
A9	9	9		
A10	9	10		
A11	9	11		
A12	9	12		



# Engineering Product Design

<b>Product Construction</b> 12 Conductor Cable Jacketed	<b>Controlled Customer Copy</b> B.W.B. GERMANY	<b>Product Description</b> <b>VG 95218 T027 B015</b>	<b>Rev</b> 2
---	--	---	-----------------

## Cabling

Layer No	Quantity	Description	Nominal O.D. mm
Layer 1	3	VG 95218 T020 A007	
Layer 2	9	VG 95218 T020 A007	8.5

## Outer

Layer Type	Description	Nominal O.D. mm
Jacket: Extrusion 1	FDR 25 - Black Marked 'Raychem - VG 95218 T027 B015 - K1010 - VDE Reg.Nr. 9424'	11.0 ±0.5 Min Wall - 1.01mm

## Cable Characteristics

Maximum Weight	280 (kg/km)
This cable is RoHS Compliant	

## Specifications

VG 95218 Part 27 Type B

## Notes

Internal Reference - EPD42514A

## Lengths

Unless otherwise specified on your order this cable may be supplied in the following maximum number of continuous lengths with no single length less than 25m:

Order Quantity (m) + One other length  
100