
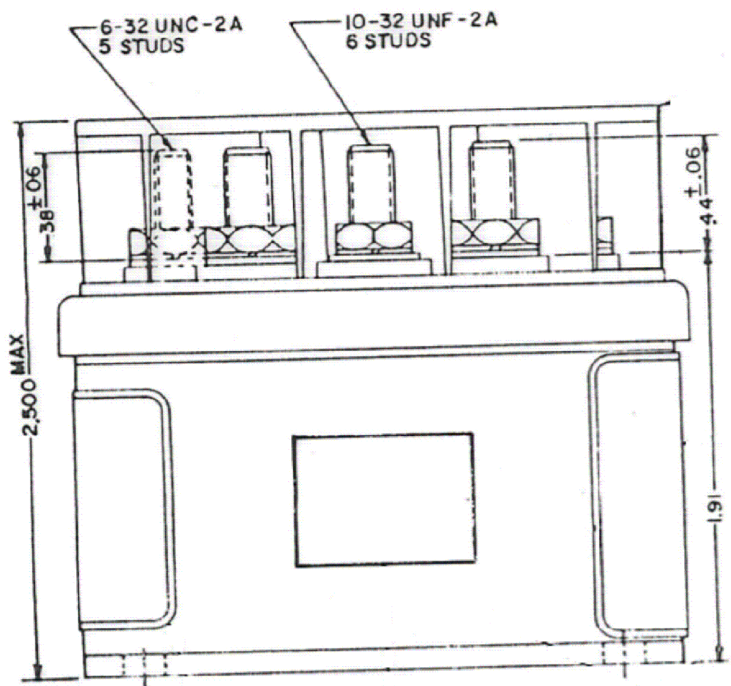


D-7VG
 CONTACTOR-3PST
 60AMP 115VAC 400Hz

REVISIONS

REV.	ECO	DESCRIPTION	DATE	APPROVED
A	-	INITIAL RELEASE	05MAY2020	RSS

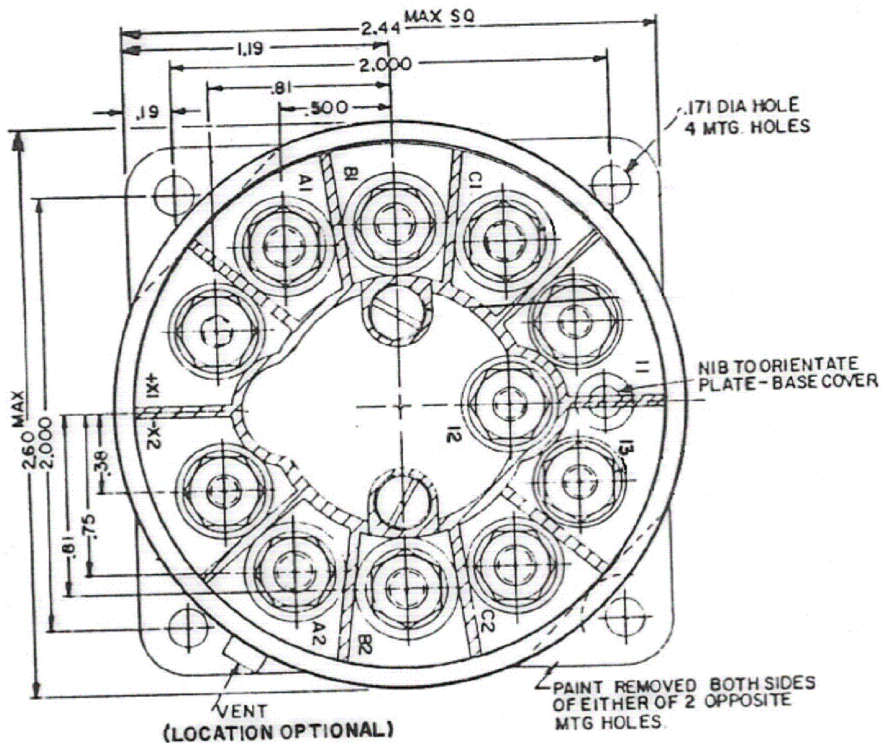

ALL DIMENSIONS ARE IN INCHES

STE
 TE CONNECTIVITY
 175 N, DIAMOND STREET MANSFIELD,
 OHIO 44902

TITLE
 CONTACTOR-3PST
 60AMP 115VAC 400Hz

TE P.N.
 1-1616933-9

DWG NO.
 D-7VG

DS DATA SHEET

CAGE CODE
 74063

SCALE
 NONE

SHEET
 1 OF 2

REV
 A


GENERAL SPECIFICATION

CONSTRUCTION	GASKET SEALED, VENTED
CONTACTS	3PST NO
CONTACT RATING, MAIN	60 AMP 115 V 400 HZ
AUX.	5 A. 28 VDC
COIL RATING	28 VDC
PICKUP	18 V
DROPOUT	1.0-7.0 VDC
RATED DUTY	CONTINUOUS
MAX OPERATING AMBIENT TEMP.	71° C
ALTITUDE	40,000 FT
MAX WEIGHT	13.5 OZ.
COIL RES, AT 25°C	126 OHM ± 10%

NOTE :

- 1) COIL TRANSIENT VOLTAGE LIMITED TO ± 45 VOLTS REFERENCED TO ZERO.
- 2) THIS UNIT MEETS THE APPLICABLE PORTIONS OF MIL-R-6106.

SCHEMATIC

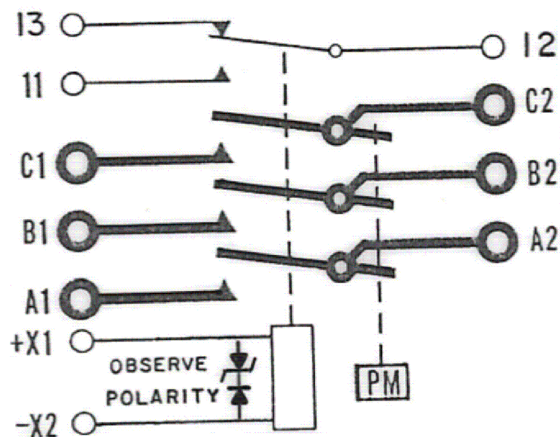

TE CONNECTIVITY
175 N. DIAMOND STREET MANSFIELD,
OHIO 44902

TITLE

CONTACTOR-3PST
60AMP 115VAC 400Hz

TE P.N.

1-1616933-9

DWG NO.

D-7VG

DS

DATA SHEET

CAGE CODE
74063

SCALE
NONE

SHEET
2 OF 2

REV
A