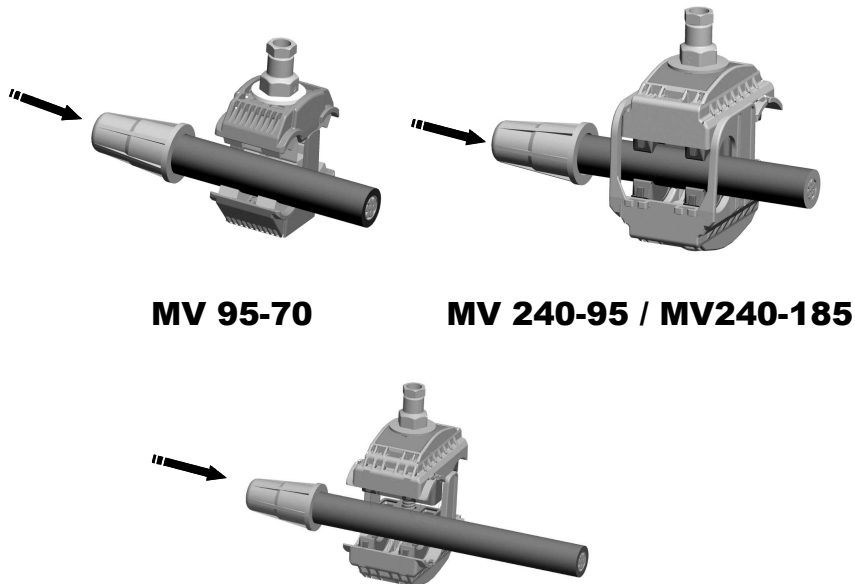
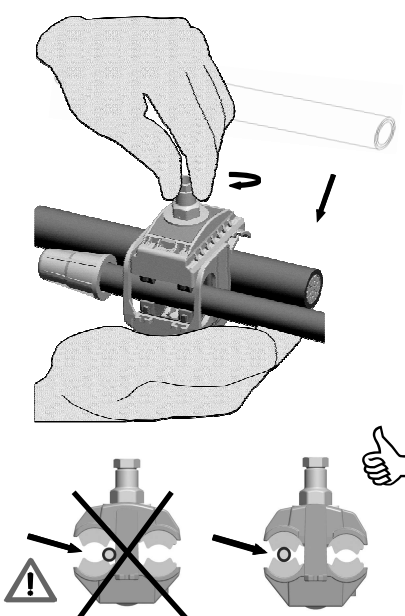
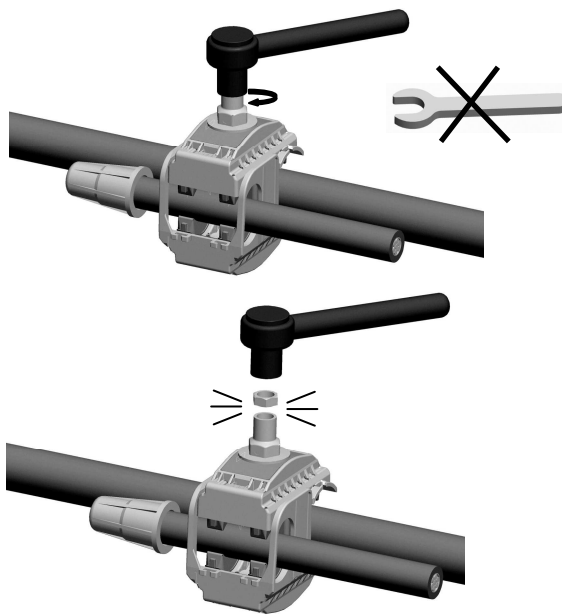


MV95-70 / MV240-95 / MV240-95G / MV240-185

Installation Instructions

安装指导

- Connectors for aluminum or copper 10kV cable (GB 14049-93)
- 适用于10kV铝或铜架空绝缘电缆 (GB 14049-93)

 MV 95-70 MV 240-95 / MV240-185 MV 240-95G 1	 2	 3
- Open the cap position to suit the direction of the branch approach; - Insert the branch conductor fully into the cap;	- Arrange the position of the connector on the main conductor, then tighten the bolt by hand;	- Finish tightening with either a 13mm or 17mm socket wrench (according to the connector marking) until the shear heads are sheared off.
- 根据支线方向调整尾盖的位置; - 将支线完全插入尾盖;	- 调整线夹在主线的位置, 然后手动拧紧扭力螺母;	- 然后用13mm或者17mm (根据连接器的标示) 的内六角套筒扳手将扭力螺母拧断。