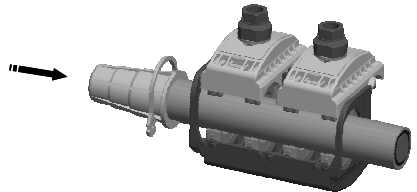
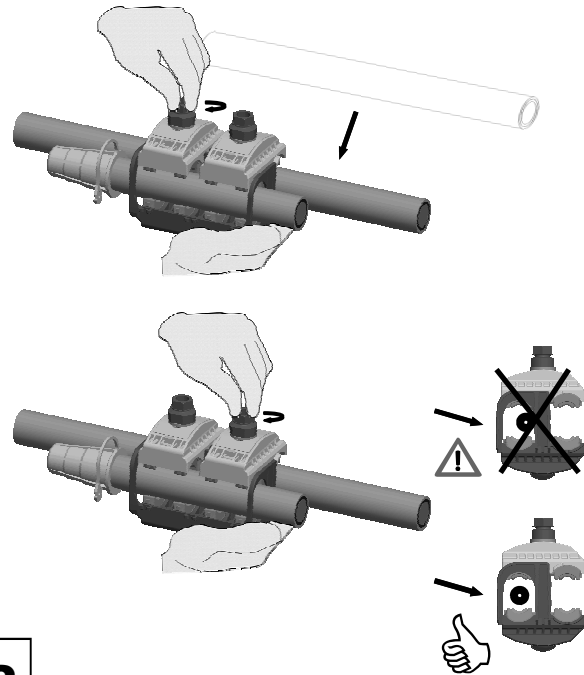
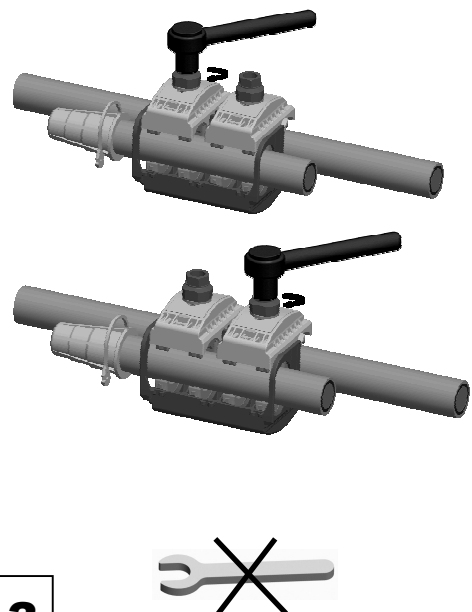
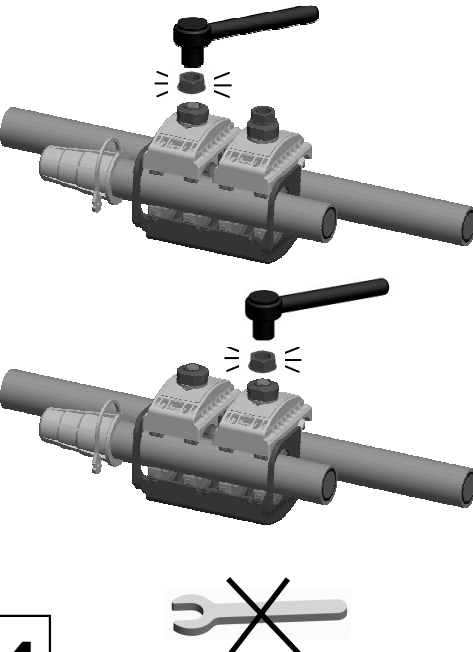


MV300-240

Installation Instructions

安装指导

- Connectors for aluminum or copper 10kV cable (GB 14049-93)
- 适用于10kV铝或铜架空绝缘电缆 (GB 14049-93)

 <p>MV300-240</p> <p>1</p>	 <p>2</p>	 <p>3</p>	 <p>4</p>
<ul style="list-style-type: none"> - Open the cap position to suit the direction of the branch approach; - Insert the branch conductor fully into the cap; 	<ul style="list-style-type: none"> - Arrange the position of the connector on the main conductor, then tighten the bolts by hand one by one; 	<ul style="list-style-type: none"> - The 2 bolts of the connector have to be tightened equally with 17mm socket wrench (according to the connector marking); 	<ul style="list-style-type: none"> - Finish tightening with socket wrench until the shear heads are sheared off one by one.
<ul style="list-style-type: none"> - 根据支线方向调整尾盖的位置; - 将支线完全插入尾盖; 	<ul style="list-style-type: none"> - 调整线夹在主线的位置, 然后手动拧紧扭力螺母; 	<ul style="list-style-type: none"> - 使用17mm (根据连接器的标示) 的内六角套筒扳手交替拧紧2个螺栓; 	<ul style="list-style-type: none"> - 继续拧紧, 直至分别拧断2个扭力螺母。