

REV. 0
 DCO 64181

COIL: @ 25°C	
SET	RESET
480 OHMS ±10%	480 OHMS ±10%
16.0 VDC NOMINAL VOLTAGE	16.0 VDC NOMINAL VOLTAGE
12.5 mADC MUST OPERATE	12.5 mADC MUST OPERATE

ENVIRONMENT:

VIBRATION 10 Hz 3000 Hz 30 g's

SHOCK 150 g's 11 MS. DURATION

TEMPERATURE -65 °C TO +125 °C


NOTES: SET AND RESET TIME 4 MS MAX.
CONTACT BOUNCE 2 MS MAX.

CUST. C.I.I. STD

CUST. NO. _____

TYPE "3SAM" RELAY

CUSTOMER DATA SHEET

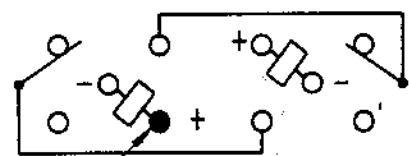

ENERGIZED LAST

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. ASB 11/12/01

CK. 11/12/01

CII Technologies
 advanced control electronic solutions

3SAM6005K2