


REV. 1

DCO 170498

COIL: @ 25°C	
RESISTANCE	2500 OHMS ± 10%
NOMINAL VOLTAGE	8.0 mADC
MUST OPERATE	4.0 mADC
MUST RELEASE	2.0 mADC MAX, .40 mADC MIN

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 15 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE TIME 15 MS MAX
	RELEASE TIME 10 MS MAX
	CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

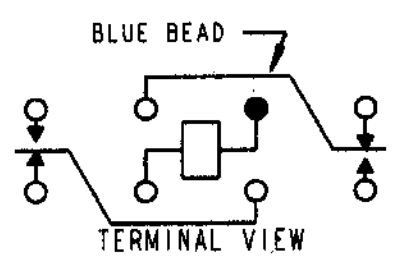

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 12/6/00

CK. TLG 06-05-01

CII Technologies
advanced control electronic solutions

CUST. OPL
CUST. NO. M5757/13-089 REV.

3SAT RELAY

3SAT1306A2