

REV. 0

DCO 170424


COIL: @ 25°C	
RESISTANCE	2500 OHMS
NOMINAL VOLTAGE	8.0 mADC
MUST OPERATE	4.0 mADC
MUST RELEASE	2.0 mADC MAX, 0.40 mADC MIN

ENVIRONMENT:

VIBRATION	10	CPS TO	2000	CPS @	15	g's
SHOCK	100	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: OPERATE 15 MS MAX  
 RELEASE 10 MS MAX  
 CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

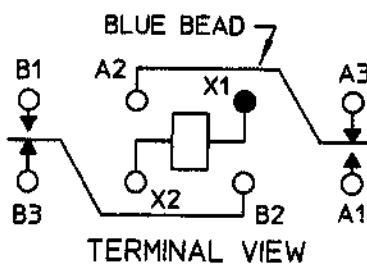

CONTACT RATING: LOW LEVEL TO 2A  
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 3/05/01

CK.TLG 3-5-01

**CII Technologies**  
 advanced control electronic solutions

CUST. QPL  
 CUST. NO. M5757/13-100 REV.

3SAT RELAY

3SAT1317A2