


REV. 0
DCO 170410

COIL: @ 25°C	
RESISTANCE	10,000 OHMS
NOMINAL VOLTAGE	4.0 mADC
MUST OPERATE	2.0 mADC
MUST RELEASE	1.0 mADC MAX, 0.2 mADC MIN

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 15 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE 15 MS MAX
RELEASE 10 MS MAX
CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

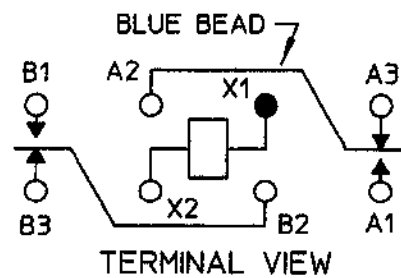

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 2/23/01 CK. TLG 02-23-01

CII Technologies™
advanced control electronic solutions

CUST. QPL
CUST. NO. M5757/13-103 REV. 3SAT RELAY

3SAT1320A2