
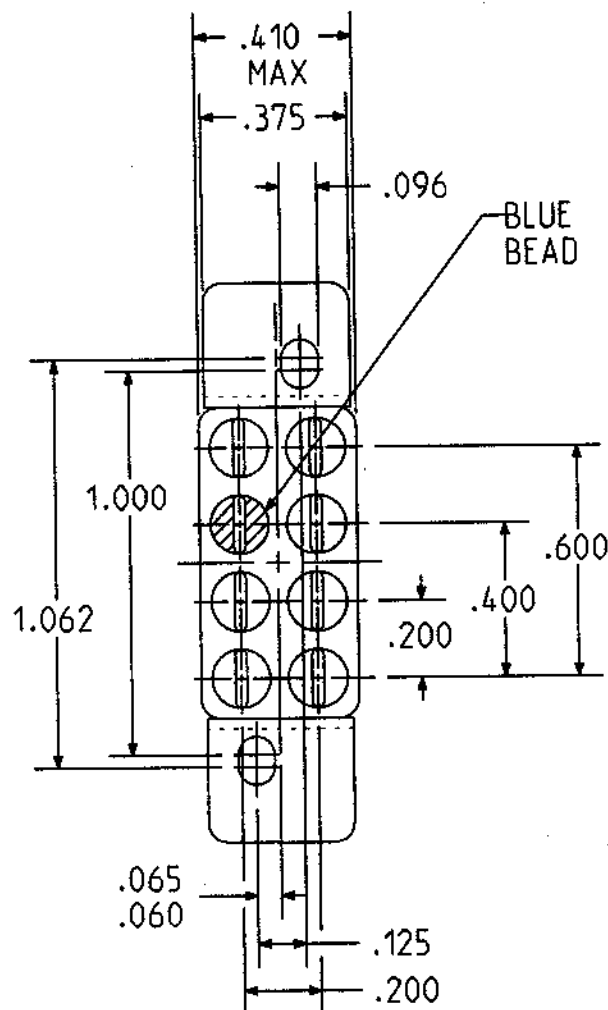


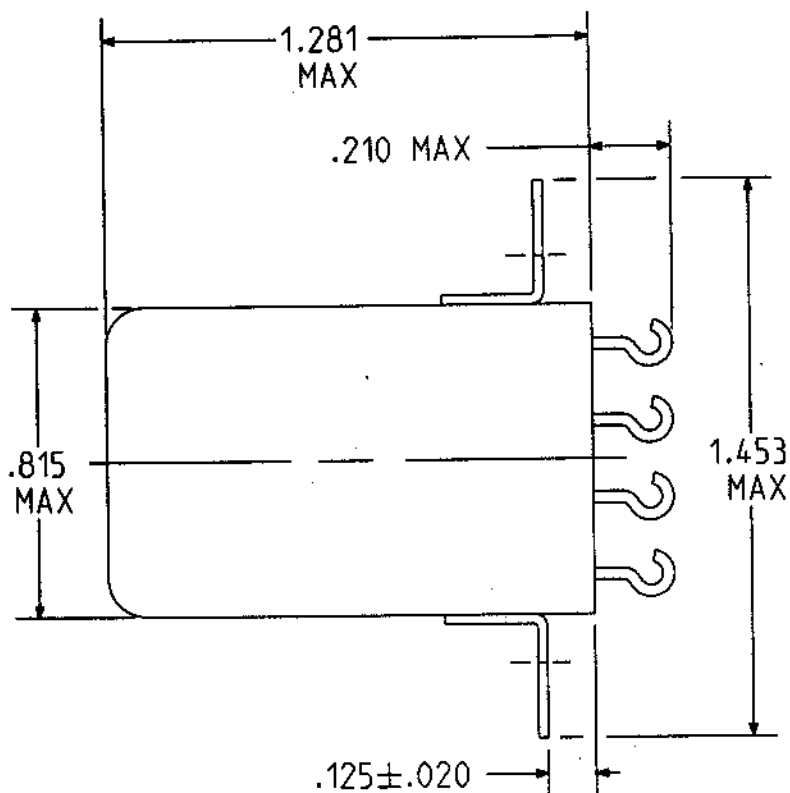

REV. 0

DCO 170675

COIL: @ 25°C
 RESISTANCE 500 OHMS ±10%
 NOMINAL VOLTAGE 18.0 mADC
 MUST OPERATE 9.0 mADC
 MUST RELEASE 4.5 mADC MAX, 0.9 mADC MIN

ENVIRONMENT:


VIBRATION 10 Hz TO 2000 Hz @ 15 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 15 MS MAX
 RELEASE 10 MS MAX
 CONTACT BOUNCE 1 MS MAX

CUST. QPL
 CUST. NO. M5757/13-106 REV.

"3SAT" RELAY

CUSTOMER DATA SHEET

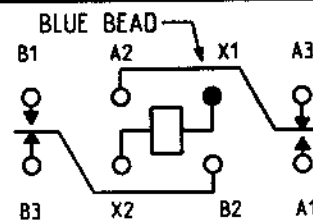

TERMINAL VIEW

CONTACT RATING: 2 AMPS 28 VDC
 RESISTIVE 100,000 OPERATIONS

DR. ASB 23 SEP 02

CK. 9/23/02

CII Technologies
 advanced control electronic solutions

3SAT1323A2