


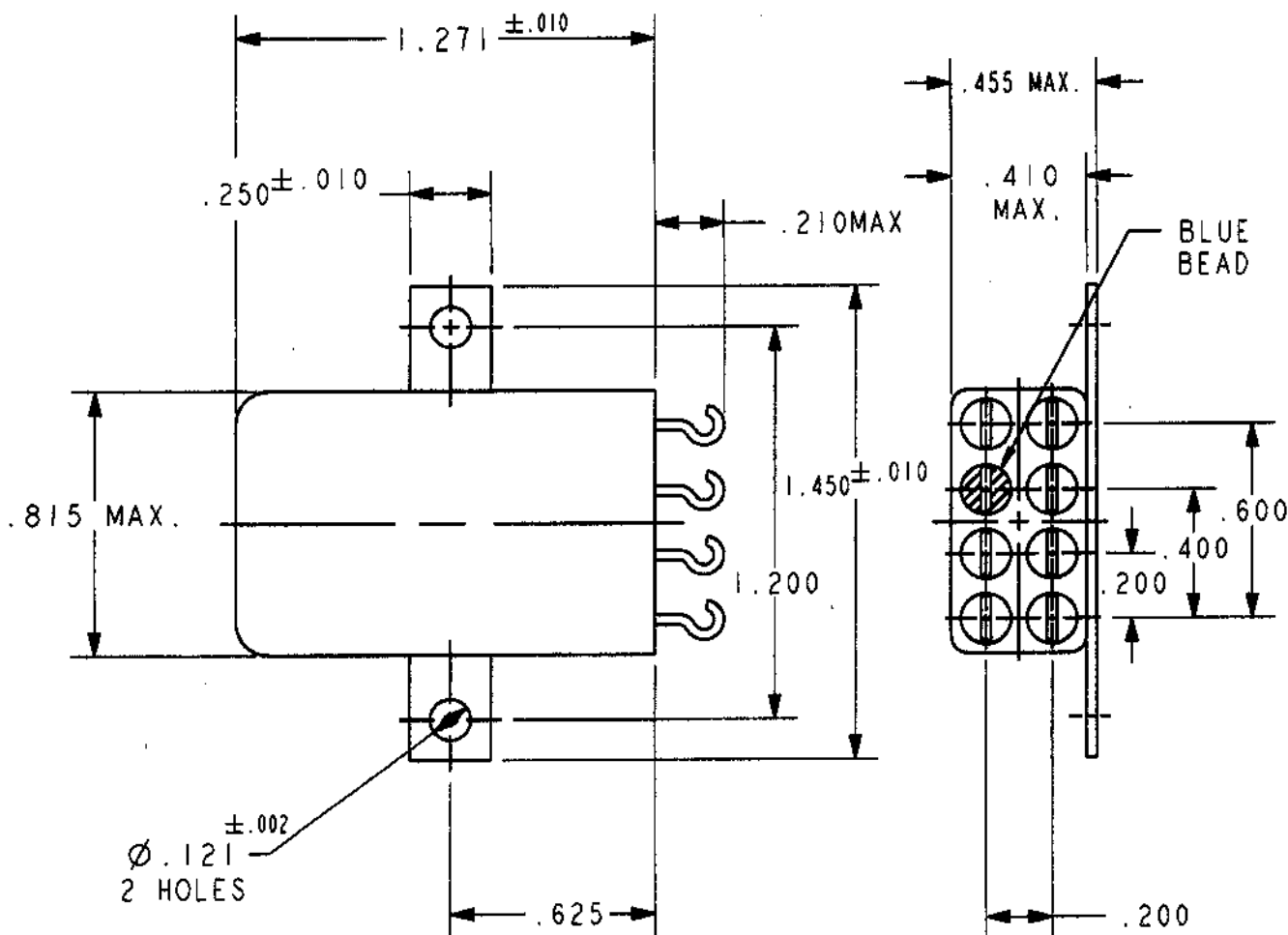

REV. 0
DCO 170526

COIL: @ 25°C
 RESISTANCE 1500 OHMS 10%
 NOMINAL VOLTAGE 11.0 mADC
 MUST OPERATE 5.2 mADC
 MUST RELEASE 2.6 mADC MAX 0.52 mADC MIN


ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 15 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 $^{\circ}\text{C}$ TO +125 $^{\circ}\text{C}$

NOTES:
 OPERATE TIME 15 MS MAX.
 RELEASE TIME 10 MS MAX.
 CONTACT BOUNCE 2 MS MAX.

CUST. QPL
 CUST. NO. M5757/13-138 REV.

3SAT RELAY

CUSTOMER DATA SHEET

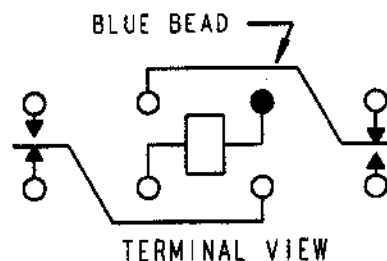

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. BSH 07/16/01 CK. TLG 7-16-01

CII Technologies
 advanced control electronic solutions

3SAT1355A2