

REV. 0


DCO 170339

COIL: @ 25°C	
RESISTANCE	2500 OHMS $\pm 10\%$
NOMINAL VOLTAGE	8.0 mADC
MUST OPERATE	4.0 mADC
MUST RELEASE	2.0 mADC MAX 0.40 mADC MIN

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 15 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-65 $^{\circ}\text{C}$ TO +125 $^{\circ}\text{C}$

NOTES: OPERATE TIME 15 MS MAX
 RELEASE TIME 10 MS MAX
 CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

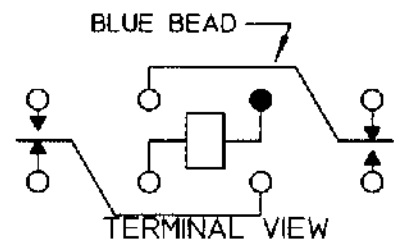

CONTACT RATING: LOW LEVEL TO
 2 AMPS 28 VDC RESISTIVE
 100,000 OPERATIONS

DR. PBB 12/6/00

CK. TLG 12-11-00

CII Technologies™
 advanced control electronic solutions

CUST. QPL
 CUST. NO. M5757/13-140 REV.

3SAT RELAY

3SAT1357A2