


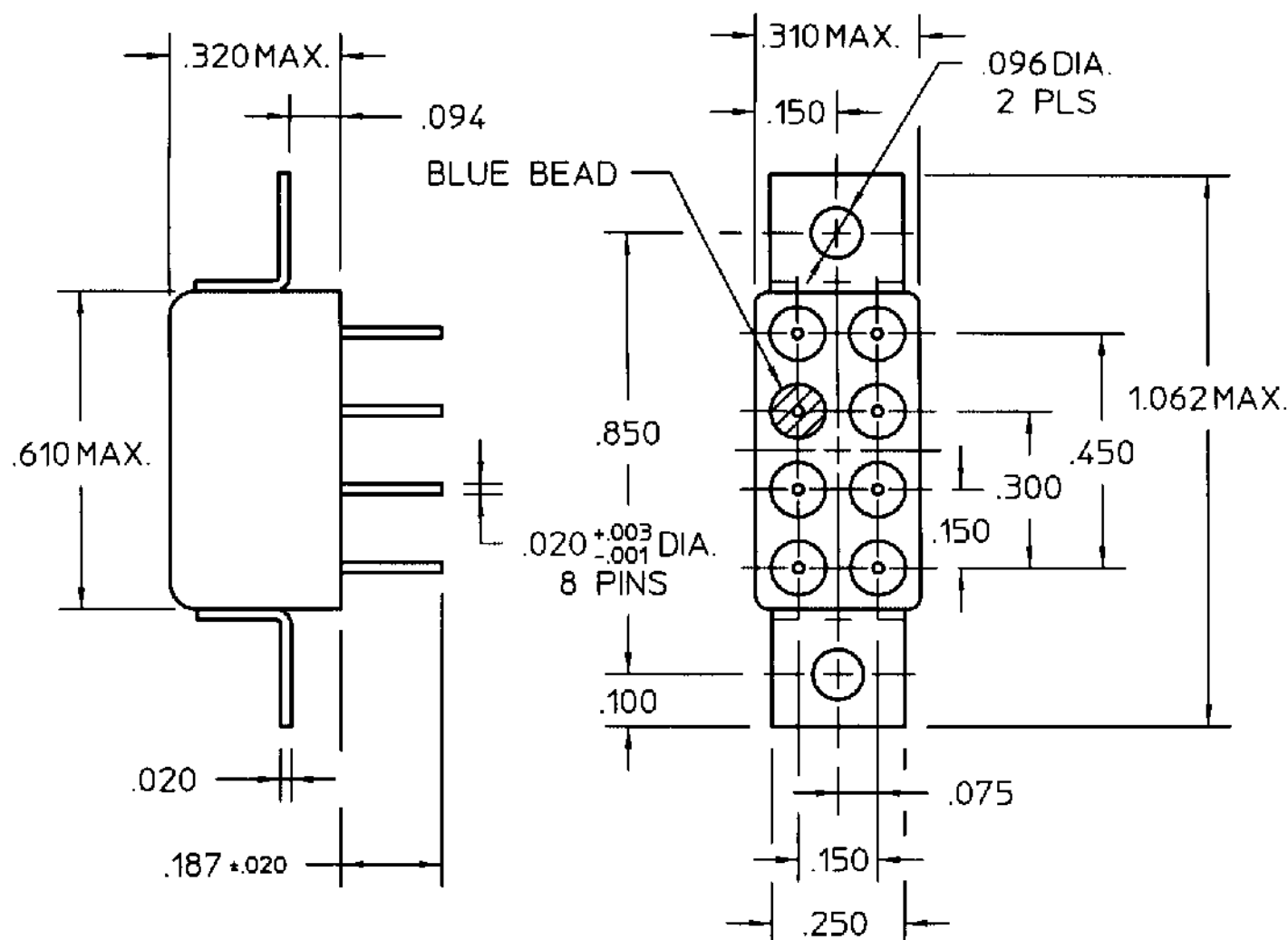

REV. 1

DCO 141326

TOL * .010 UNLESS OTHERWISE SPECIFIED


COIL: @ 25°C
 RESISTANCE 140 OHMS ± 10%
 NOMINAL VOLTAGE 9.0 VDC
 MUST OPERATE 4.4 VDC
 MUST RELEASE 2.6 VDC MAX, 0.5 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX.
 BOUNCE 2.0 MS MAX.

CUSTOMER DATA SHEET

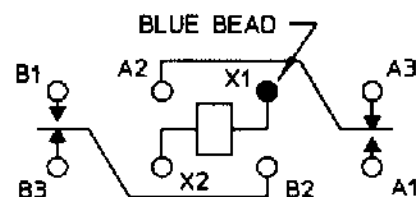

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
 2 AMPS 28 VDC RESISTIVE
 50,000 OPERATIONS

DR. R.B. 10/15/96 CK. G9H 9/20/99

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M39016/13-103L REV.

3SBC RELAY

3SBC1769A2