


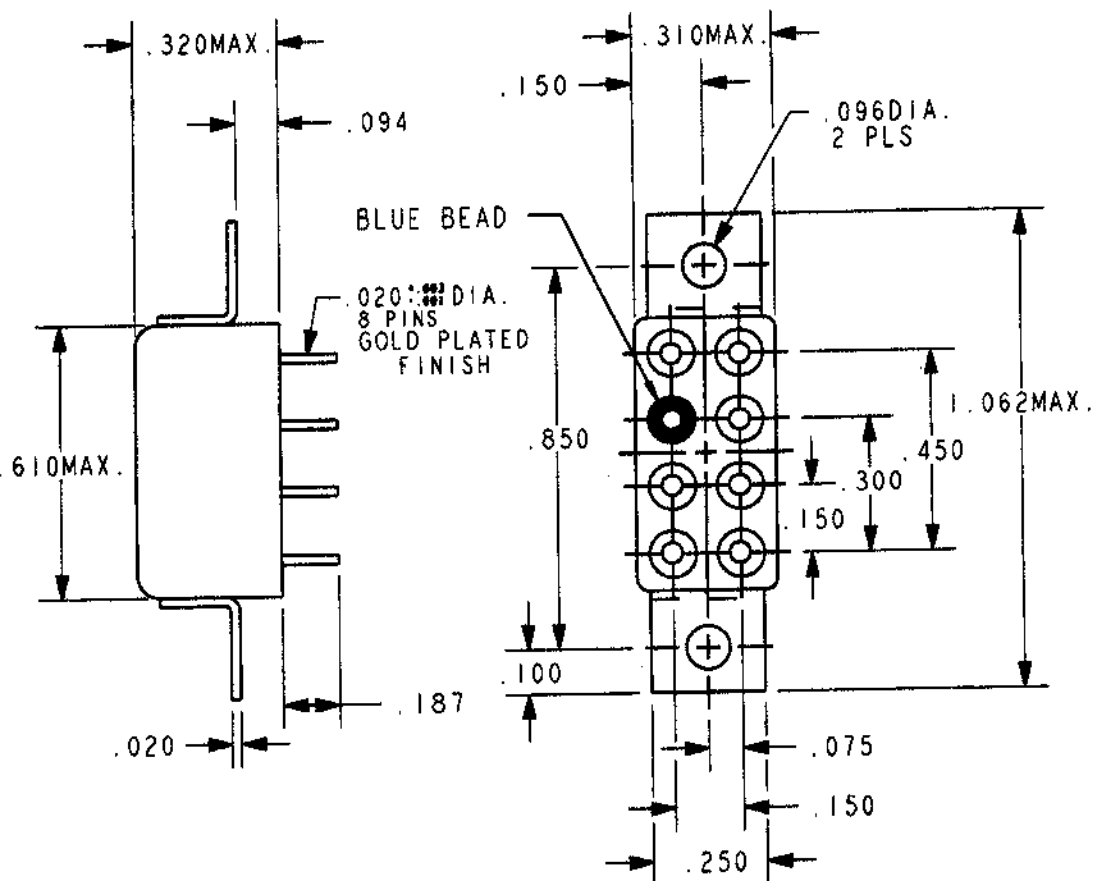

REV. 0

DC0143131

TOL ± .010 UNLESS OTHERWISE SPECIFIED

COIL @ 25°C

RESISTANCE 44 OHMS ± 10%

NOMINAL VOLTAGE 5.0 VDC

MUST OPERATE 2.4 VDC

MUST RELEASE 1.45 VDC MAX, 1.5 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's


SHOCK 75 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX.

CONTACT STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

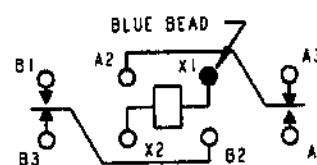

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
50,000 OPERATIONS

DR. BSH 8/01/01

CK 8/1/01

CIL Technologies
advanced control electronic solutions

CUST.

OPL

"3SBC" RELAY

CUST.

NO.

M39016/13-118P

REV.

3SBC2155A2