

REV. 0

DCO 142393


COIL: @ 25°C	2.8 OHMS ±10%
RESISTANCE	
NOMINAL VOLTAGE	6.0 VDC
MUST OPERATE	2.7 VDC
MUST RELEASE	1.6 VDC MAX., 0.3 VDC MIN.

ENVIRONMENT:

VIBRATION	10	CPS TO	3000	CPS @	30	g's
SHOCK	75	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: OPERATE 4 MS MAX.
RELEASE 4 MS MAX.
CONTACT STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

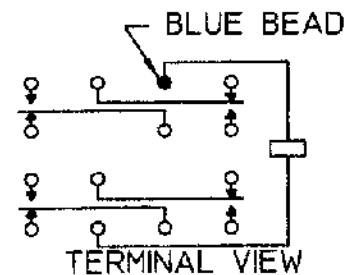

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. PBB 10/12/00

CK. 10/12/00

CH Technologies
advanced control electronic solutions

CUST. QPL
CUST. NO. M39016/14-004M REV.

3SBH RELAY

3SBH1129A2