


REV. 0  
DCO 143396

COIL: @ 25°C  
 RESISTANCE 720 OHMS ±10%  
 NOMINAL VOLTAGE 26.5 VDC  
 MUST OPERATE 14.5 VDC  
 MUST RELEASE 8.8 VDC MAX., 1.7 VDC MIN

ENVIRONMENT:  
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4 MS MAX  
RELEASE 6 MS MAX  
CONTACT BOUNCE 2.5 MS MAX

CUSTOMER DATA SHEET

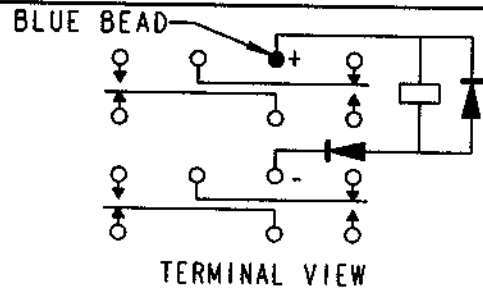

CONTACT RATING: LOW LEVEL TO  
2 AMPS 28 VDC RESISTIVE  
100,000 OPERATIONS

DR. B.D. 1/14/02 | CKV 1/14/02

**CII Technologies**  
 advanced control electronic solutions

CUST. OPL  
 CUST. NO. M39016/54-025M REV. \_\_\_\_\_

"3SBH" RELAY

3SBH1317A2