


REV. A  
DCO 143860

COIL: @ 25°C	
RESISTANCE	720 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.5 VDC
MUST RELEASE	8.1 VDC MAX., 1.5 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	
OPERATE 4 MS MAX.	
RELEASE 6 MS MAX.	
CONTACT BOUNCE 2.0 MS MAX.	

CUSTOMER DATA SHEET

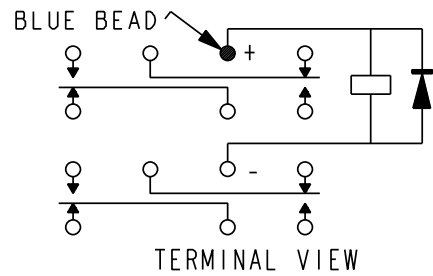

CONTACT RATING:	LOW LEVEL TO
	2 AMPS 28 VDC RESISTIVE
	100,000 OPERATIONS

DR. B.D. 11MAR04 CK. J.M.B. 3/11/04



CUST. CII STD  
CUST. NO. \_\_\_\_\_ REV. \_\_\_\_\_

"3SBH" RELAY

3SBH5131K5