


REV. A
DCO 144519

COIL: @ 25°C	
RESISTANCE	720 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.5 VDC
MUST RELEASE	8.1 VDC MAX., 1.5 VDC MIN

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE 4 MS MAX
	RELEASE 4 MS MAX
	CONTACT STABILIZATION 1.5 MS MAX

CUSTOMER DATA SHEET

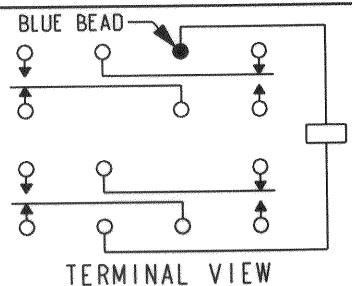

CONTACT RATING:	LOW LEVEL TO
	2 AMPS 28 VDC RESISTIVE
	100,000 OPERATIONS

DR. B.D. 11SEP2008 CKP 9/11/08

Tyco Electronics ©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CII STD	TE NUMBER	CII PART NUMBER
CUST. NO. REV.	5-1617076-1	3SBH5134K1