

REV. 0
DCO 143760

COIL: @ 25°C

CUSTOMER DATA SHEET

SET

RESET

975 OHMS ±10%

975 OHMS ±10%

26.5 NOMINAL VOLTAGE

26.5 NOMINAL VOLTAGE

14.5 MUST OPERATE

14.5 MUST OPERATE


ENVIRONMENT:

VIBRATION 10 Hz 3000 Hz 30 g's

SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4 MS MAX.
CONTACT BOUNCE 2.0 MS MAX.

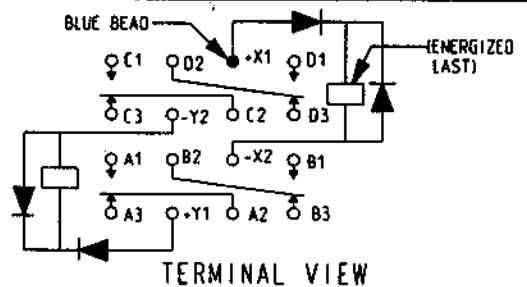

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. B.D. 16JUN03

CK. *[Signature]*

CII Technologies
advanced control electronic solutions

CUST. QPL
CUST. NO. M39016/36-006L

TYPE "3SBM" RELAY

3SBM1083A2