


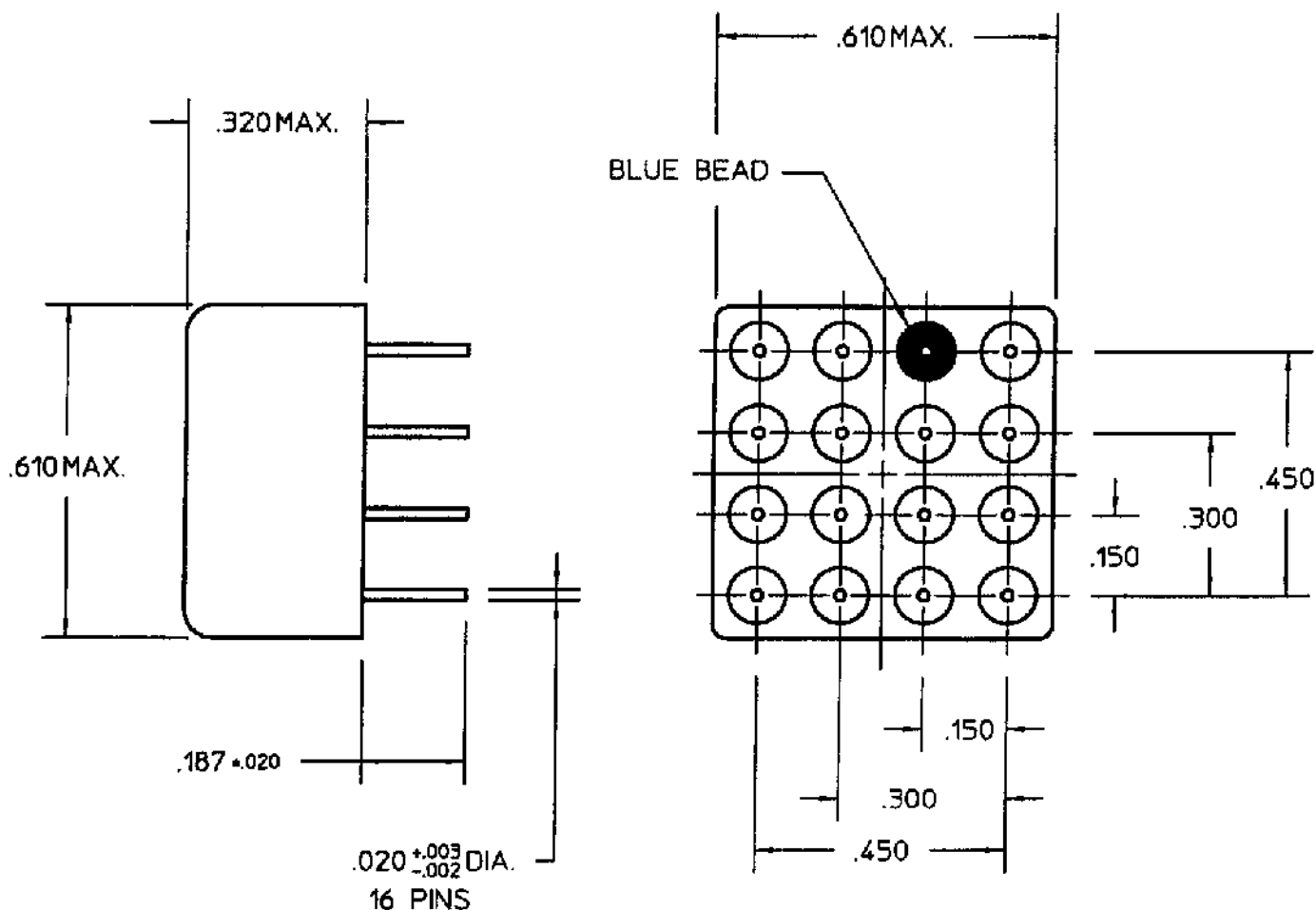

REV. 0

DCO 63293

COIL: @ 25°C

SET	RESET
145 OHMS ±10%	145 OHMS ±10%
12.0 VDC NOMINAL VOLTAGE	12.0 VDC NOMINAL VOLTAGE
6.2 VDC MUST OPERATE	6.2 VDC MUST OPERATE

ENVIRONMENT:

VIBRATION 10 Hz 3000 Hz 30 g's


SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4 MS MAX.

CONTACT STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

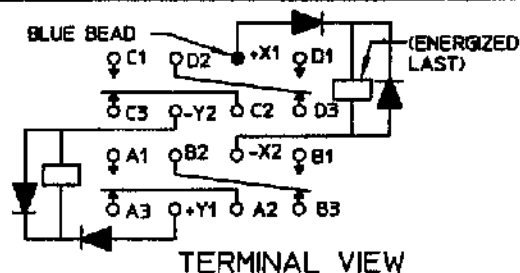

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. PBB 5-16-00

CK. 7/2/00



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/36-002M

TYPE '3SBM' RELAY

3SBM1085A2