


.020 DIA.
16 PINS

REV. 0
DCO 64170

COIL: @ 25°C

SET		RESET	
975 OHMS	±10%	975 OHMS	±10%
26.5 VDC	NOMINAL VOLTAGE	26.5 VDC	NOMINAL VOLTAGE
13.5 VDC	MUST OPERATE	13.5 VDC	MUST OPERATE

CUSTOMER DATA SHEET

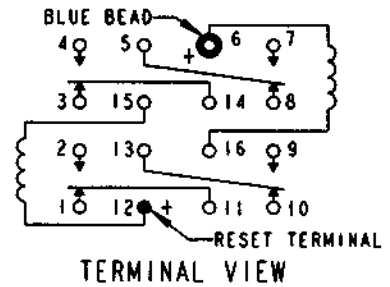

ENVIRONMENT:

VIBRATION 55 Hz 3000 Hz 30 g's
 SHOCK 150 g's 11 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: SET/RESET 4 MS MAX.
 CONTACT BOUNCE 1.5 MS MAX.

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. B.D. 10/31/01 CK. *[Signature]*



CUST. CII STD.
 CUST. NO. _____

TYPE "3SBM" RELAY

3SBM5004V2