


REV. 0
DCO 102128

COIL: @ 25°C	
RESISTANCE	300 OHMS ± 10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.0 VDC
MUST RELEASE	1.8 VDC

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 20 g's
SHOCK	50 g's 11 MS. DURATION
TEMPERATURE	-55 °C TO +85 °C

NOTES: OPERATE & RELEASE 10 MS MAX.
CONTACT BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

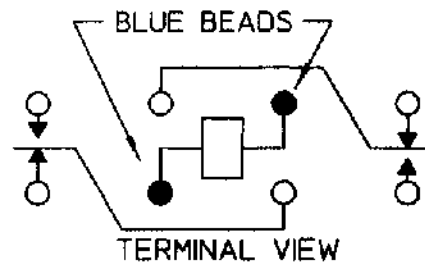

CONTACT RATING: 10 AMPS 28 VDC,
5 AMPS 115 VAC 400 Hz, RESISTIVE
100,000 OPERATIONS

DR. PBB 11/30/00 CK. TLG 11-30-00

CI Technologies™
advanced control electronics solutions

CUST. C. I. I. STD "07" RELAY
CUST. NO. REV.

B07A111BC3