


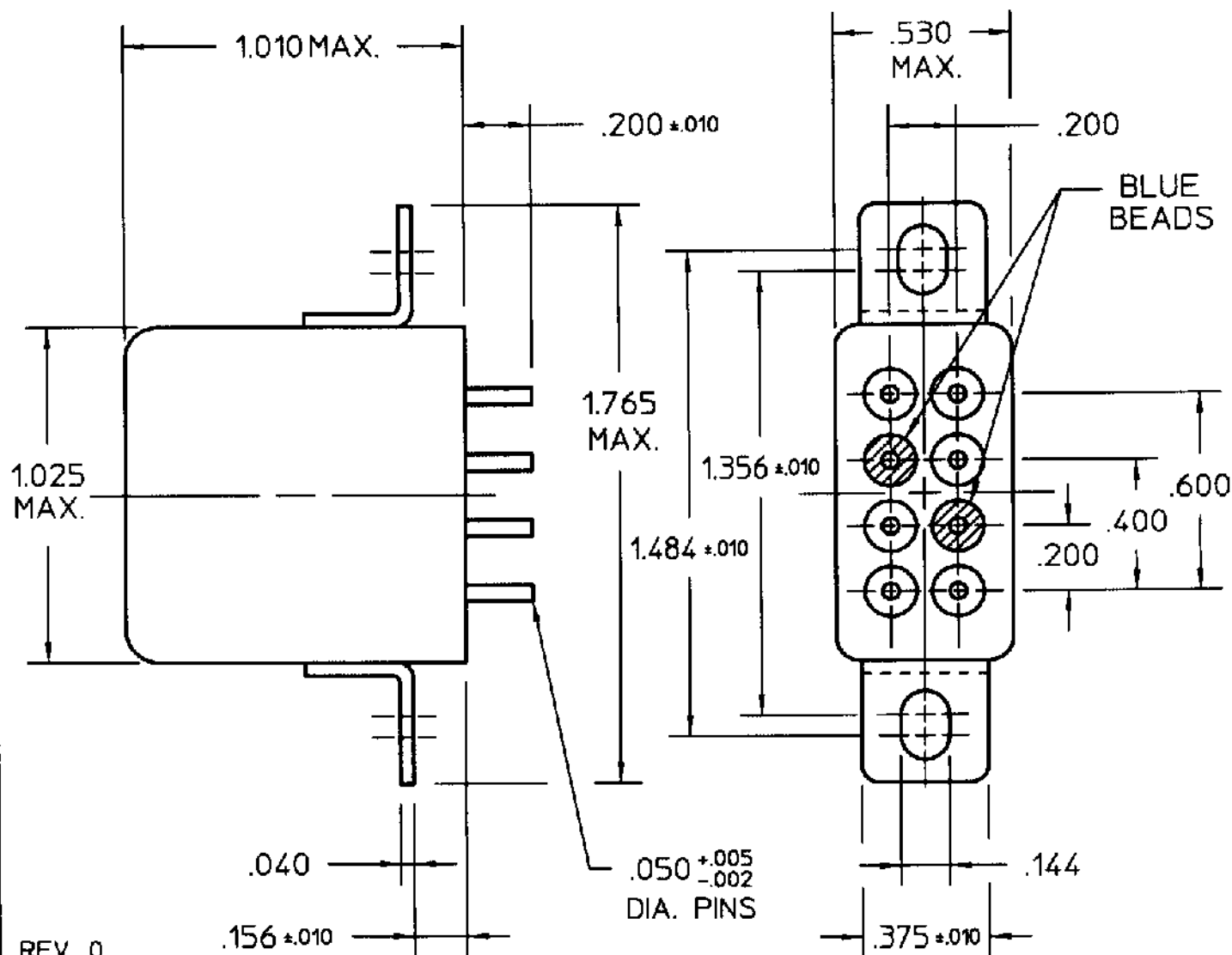


REV. 0
DCO 102128

COIL: @ 25°C
RESISTANCE 300 OHMS ± 10%
NOMINAL VOLTAGE 26.5 VDC
MUST OPERATE 14.4 VDC
MUST RELEASE 1.8 VDC

ENVIRONMENT:
VIBRATION 10 CPS TO 2000 CPS @ 20 g's
SHOCK 50 g's 11 MS. DURATION
TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE & RELEASE 10 MS MAX.
CONTACT BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

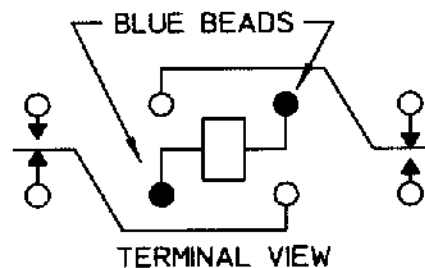

CONTACT RATING: 10 AMPS 28 VDC,
5 AMPS 115 VAC 400 Hz, RESISTIVE
100,000 OPERATIONS

DR. R.B. 4/14/99 CK. *[Signature]*



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD
CUST. NO.

TYPE "07" RELAY

B07B111AC1