


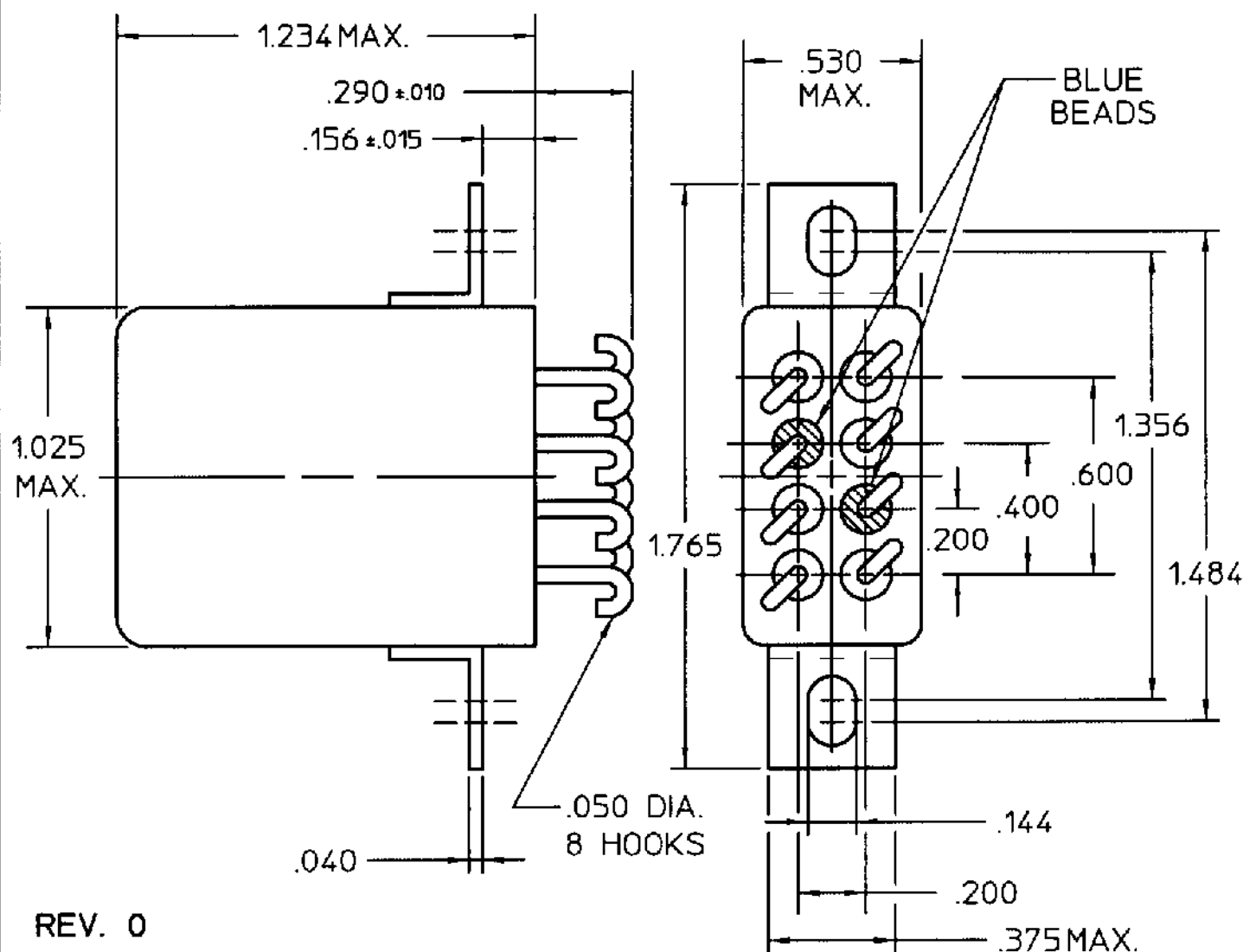

REV. 0

DCO 102352


COIL: @ 25°C
 RESISTANCE 7600 OHMS ±10%
 NOMINAL VOLTAGE 115.0 VAC (60-400 Hz)
 MUST OPERATE 75.0 VAC (60-400 Hz)
 MUST RELEASE 10.0 VAC MIN. (60-400 Hz)

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 30 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 10 MS MAX.
 RELEASE TIME 10 MS MAX.
 CONTACT BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

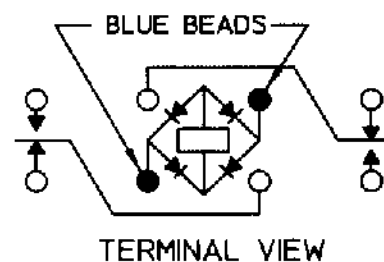

CONTACT RATING: 10 AMPS 28 VDC
 RESISTIVE 100,000 OPERATIONS
 6A 28 VDC INDUCTIVE 50,000 OPERATIONS

DR. B.D. 3/15/00

CK. G9/H 3/15/00

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C. I. I. STD.

CUST. NO. REV.

'07" RELAY

B07B142BS1