



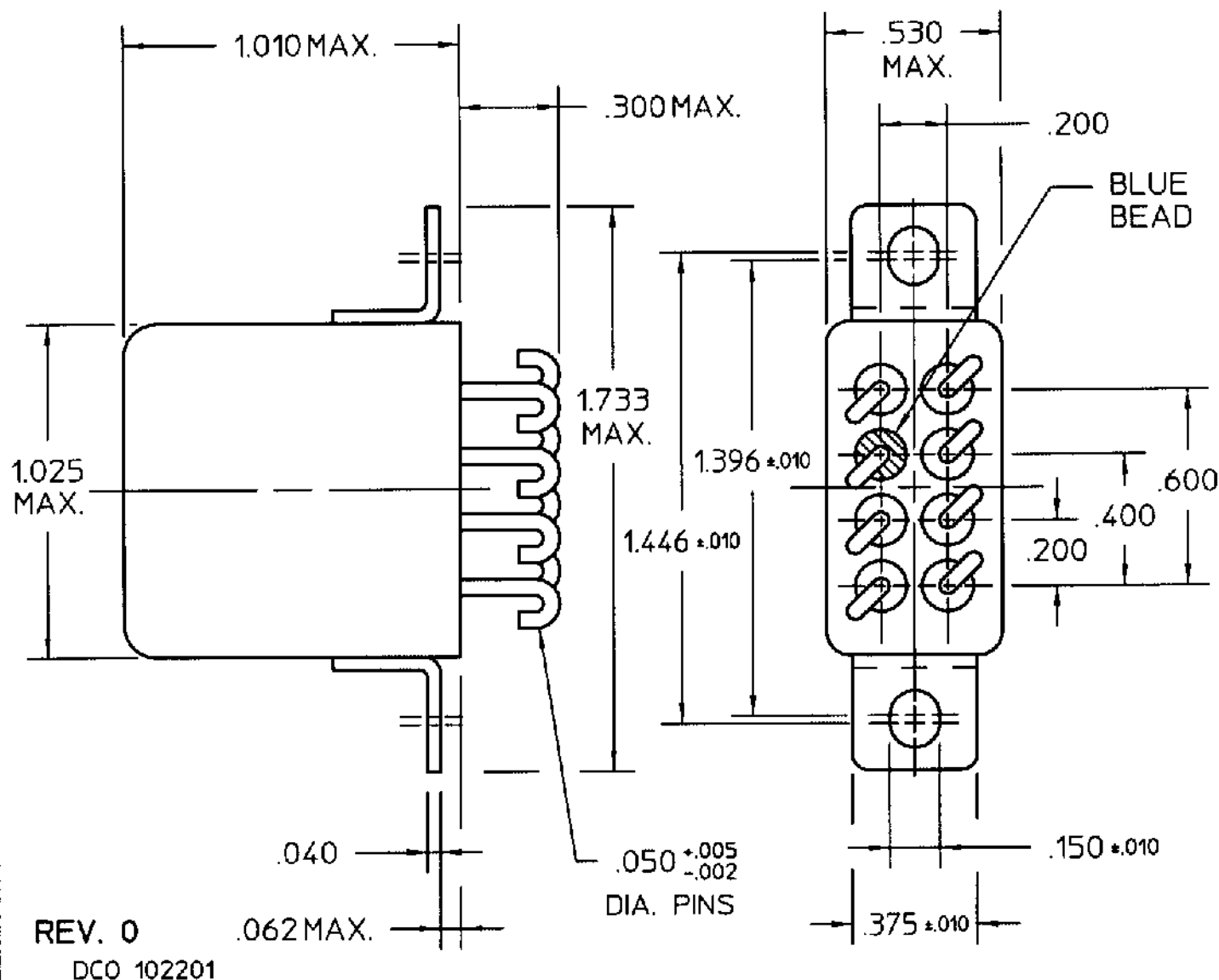

COIL: @ 25°C
 RESISTANCE 300 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 14.4 VDC
 MUST RELEASE 1.8 VDC

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 50 g's 11 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C
 NOTES: OPERATE & RELEASE 10 MS MAX.
 CONTACT BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

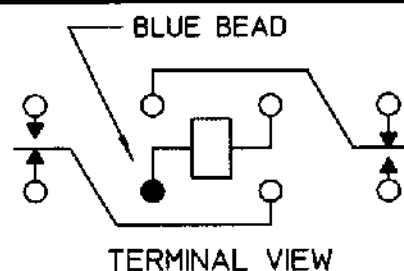

CONTACT RATING: 10 AMPS 28 VDC
 RESISTIVE 100,000 OPERATIONS

DR. B.D. 8/2/99 CK. SgH 8/2/99

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C. I. I. STD
 CUST. NO. REV.
 '07' RELAY

B07B235AC1