


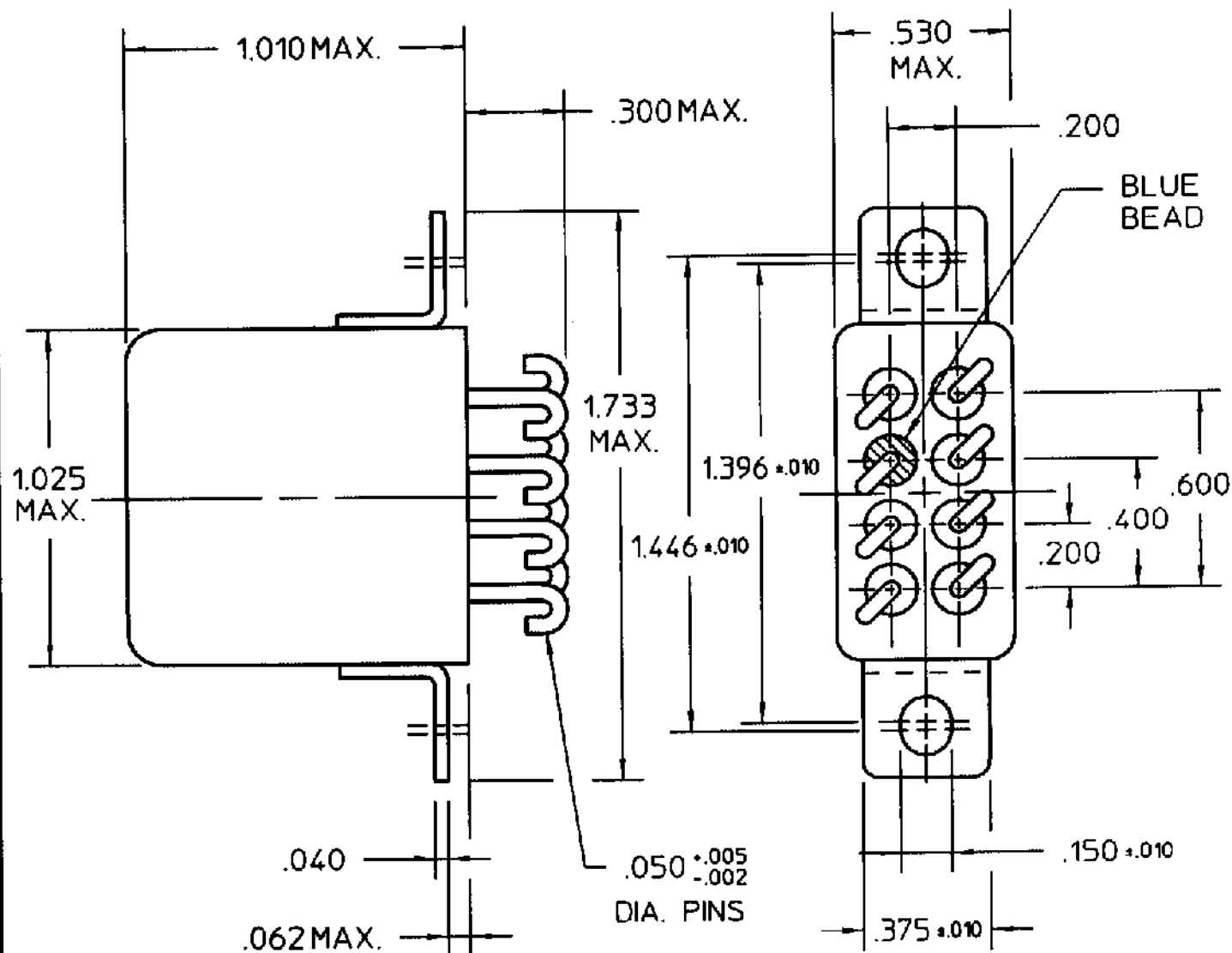

COIL:


RESISTANCE 300 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.0 VDC
 MUST RELEASE 1.8 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 50 g's 11 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 10 MS MAX.
 OPERATE BOUNCE 2 MS MAX.
 RELEASE BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

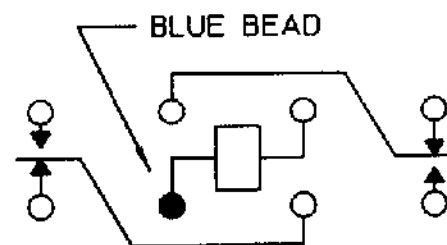

CONTACT RATING: 10 AMPS 28 VDC
 RESISTIVE 100,000 OPERATIONS

DR. R.B. 11/23/94 CK.

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. C. I. I. STD
 CUST. NO.

TYPE '07' RELAY

B07B235BC1