


REV. 1 3/1/99
DCO 102094

COIL: @ 25°C	
RESISTANCE	14-21 OHMS
NOMINAL VOLTAGE	6.0 VDC
MUST OPERATE	3.25 VDC
MUST RELEASE	1.8 VDC MAX. 0.38 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 20 g's
SHOCK	50 g's 11 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE & RELEASE 15 MS MAX.
OPERATE BOUNCE 5 MS MAX.
RELEASE BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

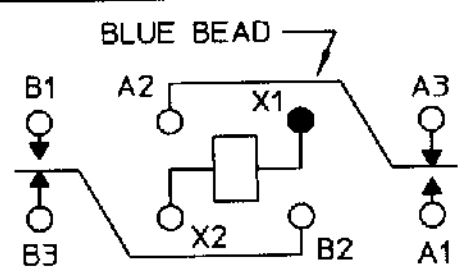

CONTACT RATING:	10 AMPS 28 VDC
	5 AMPS 115 VAC/400 Hz RESISTIVE
	50,000 OPERATIONS

DR. R.B. 7/2/97 CK3/1/02 JB



CUST. QPL
CUST. NO. M5757/23-033

TYPE '07' RELAY

B07D932BA2-0350